

Han 10B split hood

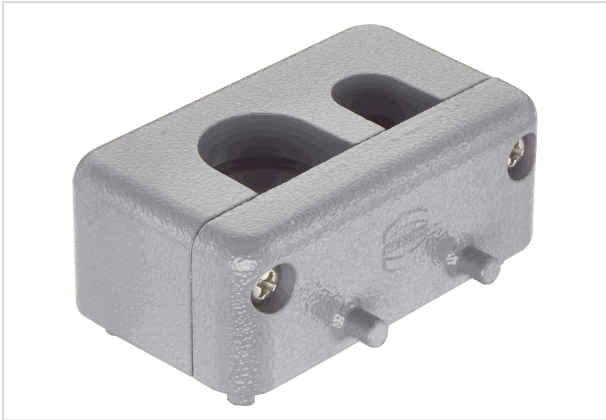


Image is for illustration purposes only. Please refer to product description.

Part number	09 30 010 0498
Specification	Han 10B split hood
HARTING eCatalogue	https://b2b.harting.com/09300100498

Identification

Category	Hoods/Housings
Series of hoods/housings	Han [®] B
Type of hood/housing	Split Hood
Type	High construction

Version

Size	10 B
Version	Top entry
Cable entry	2x
Locking type	Double locking lever
Field of application	Standard hoods/housings for industrial connectors
Details	Please order cable entry seals separately.
Pack contents	2 split hood halves 2x M4 screw

Technical characteristics

Limiting temperature	-40 ... +125 °C
Degree of protection acc. to IEC 60529	IP65

Material properties

Material (hood/housing)	Aluminium die-cast
Surface (hood/housing)	Powder-coated
Material (seal)	NBR



Pushing Performance
Since 1945

Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R1 (HL 1-3) R7 (HL 1-3)

Specifications and approvals

CE	Yes
----	-----

Commercial data

Packaging size	1
Net weight	80 g
Country of origin	China
European customs tariff number	85389099
GTIN	5713140164499
eCl@ss	27440202 Shell for industrial connectors