
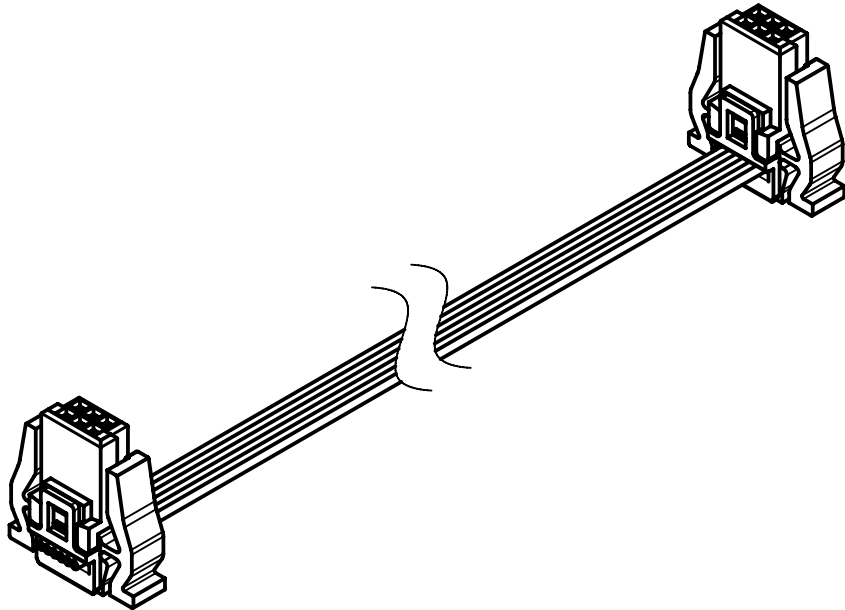
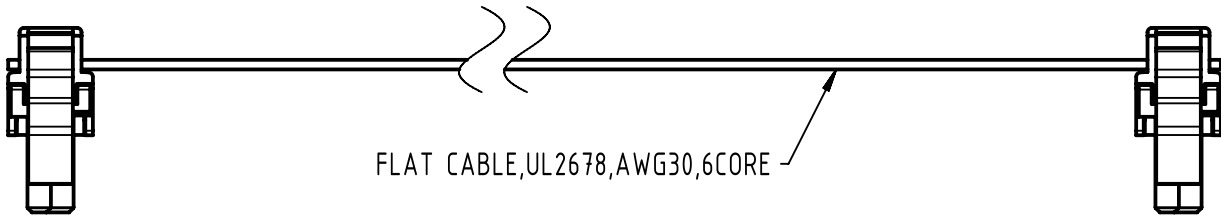
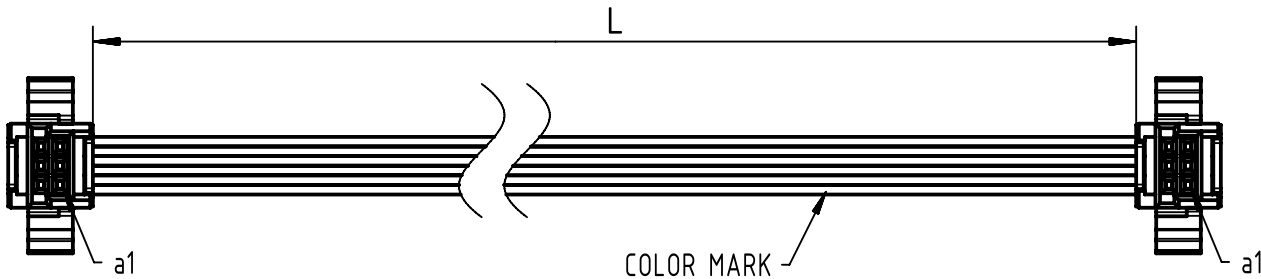


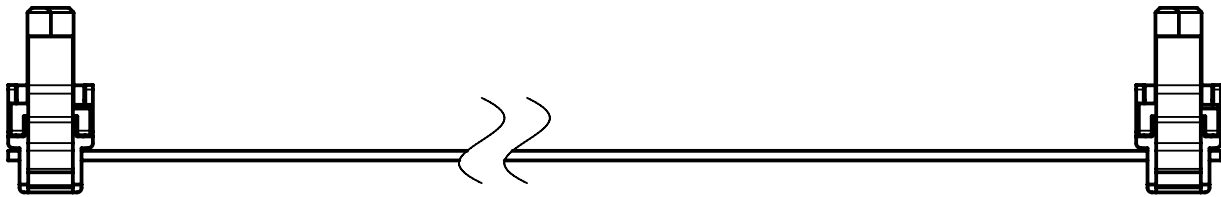

HAR-FLEX 6P FEMALE IDC CONNECTOR

HAR-FLEX 6P FEMALE IDC CONNECTOR

 
WIRING TABLE

C1	WIRE	C2
1	AWG 30	1
2	AWG 30	2
3	AWG 30	3
4	AWG 30	4
5	AWG 30	5
6	AWG 30	6

HARTING P/N	Cable length(L)
33152430100380	100 ± 3
33152430200380	200 ± 5
33152430500380	500 ± 5

NOTES:

- 1.)CABLE MUST BE PERFORMED 100% CONTINUITE TEST AND HI-POT TEST.
- 2.)CABLE OPERATION TEMPERATURE: -20°C TO +105°C
- 3.)CABLE SHOULD BE PACKED BY PLASTIC BAG,THEN PUT IT INTO CARTON (QTY ACCORDING TO ACTUAL CONDITION).
EXPORT CARTON SHOULD BE STICKED A LABEL WITH P/N AND QTY.

		All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
All rights reserved		Created by LIN Lin		Inspected by QINL Qin		Standardisation QINL Qin		Date 2019-08-03	
Department HCS - CN		Title Har-flex 6Pole,Dul-end,W/O SR,L=XXmm		State Final Release		Doc-Key / ECM-Nr. 100749026/UGD/008/A 500000156071		Rev. A	
HARTING Customised Solutions		Type TB		Number 33 15 243 XXX0380		Page 1/1			
D-32339 Espelkamp									