

Highlights

- **4 speed levels**
low, medium, high, very high
- **Internal swivelling function**
The swivelling function distributes the cooled air optimally to all areas of the room.
- **Cooling effect**
Cools the room air drawn in by up to 8°C
- **Air purifier**
The sucked-in air is washed through the filter. Dust, pollen, mites, bacteria and unpleasant odours are filtered out of the air.
- **Anion**
Ionisers in air purifiers generate negatively charged ions (anions), which combine with positively charged dirt particles in the room air to form larger clusters.
- **63 litre water tank**
Operation up to 10 hours possible.



This powerful air cooler with an impressive 63-litre water tank provides perfect cooling on hot days. The room air drawn in is cooled by an impressive 8°C.

Thanks to the 4 different speed levels and a special cooling mode, you can customise the room climate to suit your needs.

The easily accessible water tank can be filled effortlessly and operation is child's play using the remote control supplied or the touch panel on the appliance.

Washable dust and water filters and an integrated ioniser ensure thorough cleaning of the air and neutralise unpleasant odours. The air drawn in is cleaned by the filters, effectively removing dust, pollen, mites, bacteria and unpleasant odours from the air.

The swivelling function ensures optimum distribution of the cooled air in all areas of the room.

The timer function allows you to switch the appliance off at a specific time.

Note: Due to the high humidification performance of the appliance, a sufficient supply of air is required indoors. The appliance is particularly suitable for use in workshops, well-ventilated rooms and outdoors.



Scope of delivery

- Air cooler
- Remote control
- Operating instructions

Warranty period

- 2 years




Front view



Oblique view



Rear view

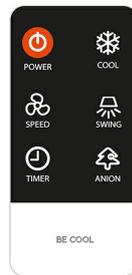

Remote control

Specifications:

- 3 in 1: cooling, humidification, ventilation
- Air circulation 5,500 m³/h
- Effective area 45 m²
- Power consumption 205 watts (1.00 A)
- Water tank volume 63 litres
- Direct water connection possible
- Operating time with full tank 7 - 10 hours
- Water evaporation 6.0 to 9.0 litres per hour
- 4 levels
- Air purifier with ioniser (anion)
- Special rotor blade
- Castors
- Easy to fill water tank
- Touch control panel

Dimensions:

- Product (W×H×D): 610×1250×462 mm
- Packaging (W×H×D): 650×1290×510 mm
- Net/gross weight: 23 kg / 26.4 kg

