

# Product Datasheet

**Product code:** **00D.SA.0**

**Product type:** High precision tweezers

**Made in:** Switzerland


**Description:** Type 00D high precision tweezers are suitable to applications which require holding a component very firmly. The line serration provides the tips and the handles with extra grip, also preventing any possible slips.

**Tip description:** straight, thick, squared, strong, line serrated, superior finish

**Coating/finishing:** Sandblasted

**Body material:** Anti-Magnetic Anti-Acid Stainless Steel (SA)


**Picture:**

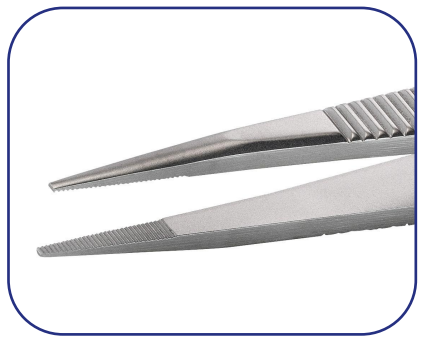

**Tweezer dimensions:**

OAL	120.0 mm – 4.724 inch
Width	10.0 mm – 0.394 inch
Height	12.0 mm – 0.472 inch

**Tip details:**

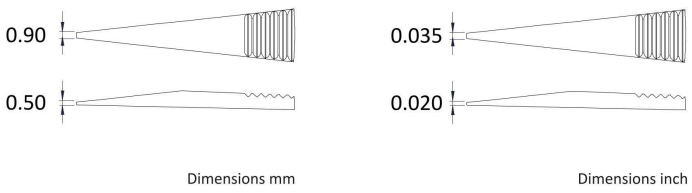

**Tip dimensions:**

Tip width	0.90 mm – 0.035 inch
Tip thickness	0.50 mm – 0.020 inch