

## Product Datasheet


<b>Product code:</b>	<b>SS.SA.0</b>
<b>Product type:</b>	High precision tweezers
<b>Made in:</b>	Switzerland
<b>Description:</b>	Type SS high precision tweezers are suitable to delicate applications which require holding a small component firmly while granting good visibility.
<b>Tip description:</b>	straight, very fine, very sharp, superior finish
<b>Coating/finishing:</b>	Sandblasted
<b>Body material:</b>	Anti-Magnetic Anti-Acid Stainless Steel (SA)

**Picture:**



<b>Tweezer dimensions:</b>	OAL	140.0 mm – 5.512 inch
	Width	8.0 mm – 0.315 inch
	Height	12.0 mm – 0.472 inch

**Tip details:**

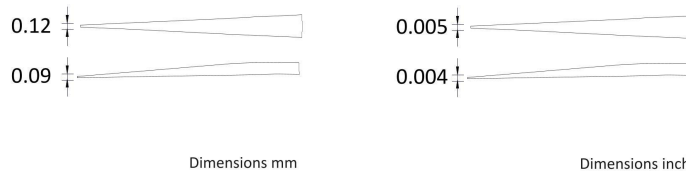

<b>Tip dimensions:</b>	Tip width	0.12 mm – 0.005 inch
	Tip thickness	0.09 mm – 0.004 inch