


Expandable PET Braided Sleeving (bulk stock)

No.: 23CA203...216

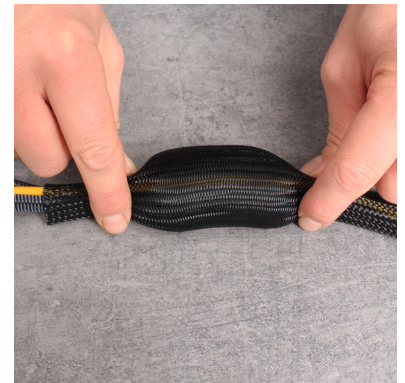

This cable braided sleeve is the optimal and cost-effective solution when it comes to protecting and bringing together cables and wires. This high flexible cable sleeving can also be used as an abrasive protection and as an inhibitor of animal bites. The woven braid hugs the contents and keeps them together, protected and clean. The material is weather resistant, durable and looks good doing it! The application is very simple and can be customized by shortening to the desired length. The cut can be made using the hot cutting method or by means of scissors / string cutter and subsequent heat sealing of the open ends.

To prevent fraying, the sleeve should be cut with a hot cutting tool!

Technical data: Material: polyester braid, high flexible (PET) • Temperature range: -55 ... 155 °C • Melting temperature: 230 °C • Color: black • RoHS compliant, REACH compliant, halogen free • Flammability class based on UL94HB.

Part-No.	Description	Expansion range	Flat width	Selling unit	Complete reel	
					Content / max. length	EAN/GTIN
23CA203	Expandable Braided Sleeve 1...6 mm, Black (1000 m)	1 ... 6 mm	4 mm	1 m +	500 m	4260732284277
23CA204	Expandable Braided Sleeve 4...8.5 mm, Black (500 m)	4 ... 8,5 mm	6 mm	1 m +	500 m	4260732284284
23CA205	Expandable Braided Sleeve 5...16 mm, Black (350 m)	5 ... 16 mm	8 mm	1 m +	350 m	4260732284291
23CA206	Expandable Braided Sleeve 7...19 mm, Black (350 m)	7 ... 19 mm	10 mm	1 m +	350 m	4260732284307
23CA207	Expandable Braided Sleeve 8...24 mm, Black (250 m)	8 ... 24 mm	12 mm	1 m +	250 m	4260732284314
23CA208	Expandable Braided Sleeve 10...27 mm, Black (200 m)	10 ... 27 mm	16 mm	1 m +	200 m	4260732284321
23CA209	Expandable Braided Sleeve 14...30 mm, Black (200 m)	14 ... 30 mm	20 mm	1 m +	200 m	4260732284338
23CA210	Expandable Braided Sleeve 18...35 mm, Black (200 m)	18 ... 35 mm	25 mm	1 m +	200 m	4260732284345
23CA211	Expandable Braided Sleeve 20...55 mm, Black (150 m)	20 ... 55 mm	32 mm	1 m +	150 m	4260732284352
23CA212	Expandable Braided Sleeve 30...60 mm, Black (100 m)	30 ... 60 mm	38 mm	1 m +	100 m	4260732284369
23CA213	Expandable Braided Sleeve 35...75.5 mm, Black (100 m)	35 ... 75,5 mm	45 mm	1 m +	100 m	4260732284376
23CA214	Expandable Braided Sleeve 40...80 mm, Black (100 m)	40 ... 80 mm	50 mm	1 m +	100 m	4260732284383
23CA215	Expandable Braided Sleeve 45...105 mm, Black (100 m)	45 ... 105 mm	64 mm	1 m +	100 m	4260732284390
23CA216	Expandable Braided Sleeve 63.5...120.7 mm, Black (100 m)	63.5 ... 120.7 mm	76 mm	1 m +	100 m	4260732284406