

The air-cooled MIG/MAG welding torches meet the needs of welders for a wide range of welding tasks.

### DESCRIPTION

Light and handy torch.  
For car bodywork and fine sheet metal work.  
Economical and safe solution.  
Small footprint.

### FEATURES

- **Max current (I<sub>max</sub>):** 180 A: CO<sub>2</sub> and 150 A: Ar/CO<sub>2</sub>  
*In pulsed mode, these capacities are reduced by 35%.*
- **Duty cycle :** 150 A @ 60 %.
- **Recommended wire diameters:** 0.6 to 1.0 mm
- **Length:** 3 m



### CONSUMABLES

#### Torch



#### Contact tube supports & diffusers




#### Contact tubes



|       | STEEL    | ALU      |
|-------|----------|----------|
| Ø 0.6 | 041905   | -        |
| Ø 0.8 | 041912 ● | 041059 ● |
| Ø 1.0 | 041929   | 041066   |
| Ø 1.2 | 040144   | 041073   |

#### Nozzles

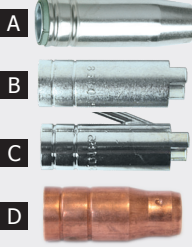

|   | ACIER    | ALU                              |
|---|----------|----------------------------------|
| A | 041875 ● | 041875 (Ø 12) ●<br>046214 (Ø 16) |
| B | 041851   | 041851                           |
| C | 041523   | -                                |
| D | 041868   | -                                |

#### Sheath

|        | Ø 0.6/0.8 |        | Ø 1.0 & 1.2 |        |
|--------|-----------|--------|-------------|--------|
|        | 3 m       | 4 m    | 3 m         | 4 m    |
| Steel  | 041592 ●  | 041837 | 041608      | 041844 |
| Teflon | 041578 ●  | 044050 | 041585      | 044067 |
| Carbon | -         | 039834 | -           | 039827 |

#### Consumables box option:

Ref. 041226

|   |   |
|---|---|
|  | x3  |
|  | x5  |
|  | x5 (M6-Ø 0.6)<br>x5 (M6-Ø 0.8)<br>x5 (Alu-M6-Ø 0.8) |
|  | x3  |



- Original steel equipment
- Original aluminium equipment