


The air-cooled MIG/MAG welding torches meet the needs of welders for a wide range of welding tasks. The GRIP handle's anti-slip coating and new ball joint provide you with exceptional working comfort.

DESCRIPTION

Ideal For car bodywork and fine sheet metal work. New ergonomic handle with «GRIP» coating for a secure grip even in difficult positions.

FEATURES

- **Max current (Imax):** 180 A: CO2 and 150 A: Ar/CO2
In pulsed mode, these capacities are reduced by 35%.
- **Duty cycle:** 150 A @ 60 %.
- **Recommended wire diameters:** 0.6 to 1.0 mm
- **Length:** 3 m

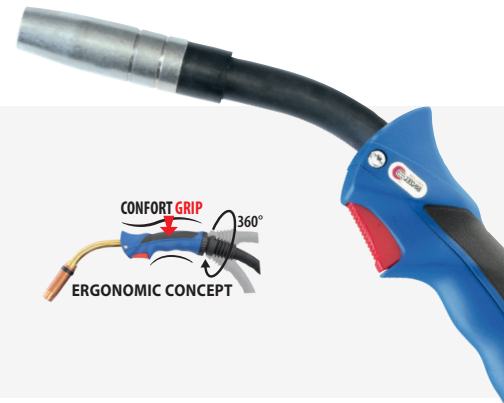

CONSUMABLES

Torch



Contact tube supports & diffusers



042902



042988

Contact tubes



	STEEL	ALU
Ø 0.6	041905	-
Ø 0.8	041912 ●	041059
Ø 1.0	041929	041066
Ø 1.2	040144	041073

Nozzles

- A welding
- B pointing
- C soda nail
- D no gas

	STEEL	ALU
A	041875 ●	041875 (Ø 12) 046214 (Ø 16)
B	041851	041851
C	041523	-
D	041868	-

Sheath

	Ø 0.6/0.8		Ø 1.0 & 1.2	
	3 m	4 m	3 m	4 m
Steel	041592 ●	041837	041608	041844
Teflon	041578	044050	041585	044067
Carbon	-	039834	-	039827

Consumables box option:

Ref. 041226

- x3
- x5
- x5 (M6-Ø 0.6)
- x5 (M6-Ø 0.8)
- x5 (Alu-M6-Ø 0.8)
- x3

