

# Hard hat with ear & eye protection shade

## 5-8/9-13



Ref. 080607

**This multifunction welding mask provides 3 levels of protection at the same time:**

- an automatic filter protects the users face and eyes against UV, infrared, and welding spatter
- an ultra-light polyethylene hard hat capable of absorbing the impact of falling objects
- Hearing protection to significantly reduce excessive noise (-30 db).

### FEATURES

#### Automatic filter:

- compatible with MIG/MAG, TIG, MMA, plasma cutting and grinding processes
- high sensitivity with 4 sensors
- settings: sensitivity, delay, shade, grinding
- adjustable shades 5-8 / 9-13
- TrueColor-technology filter delivers a more realistic and detailed colour reproduction than conventional filter systems:



Classic

TrueColor






Classification	1/1/1/2
Light shade	4
Dark shades	5 >8 - 9 >13
Reaction time	0,4 ms
Light recovery time	0,10 > 1 sec
Viewing field	100 x 52 mm
Power	solar powered & one batterie (CR2023)
Settings	Sensitivity, delay, shade, grinding
Light sensor	4
Application scope	MMA 5 >400 / TIG 5 >300 / MIG-MAG 5 >400
Standards	CE / EN 1755 / EN 166 / EN 379

#### Helmet:

- size (head circumference): 54-61 cm
- material: HDPE
- flexible, adjustable headband, supplied with sweatband
- EN 397, EN 50365


#### Noise-cancelling ear protection:

- 30 dB noise reduction (SNR)
- ultra-comfortable with soft PVC padding
- adjustable position and height
- EN 352

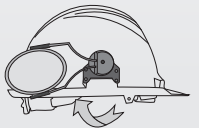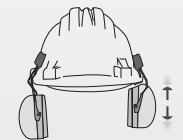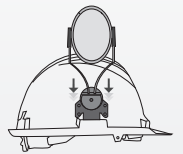

### ACCESSORIES (OPTIONAL)

 Lenses



110 X 90 (x5)	040816 106 x 59 (x10) 082137



<b>1</b>		Sensitivity adjustment
<b>2</b>	9-13 (5-8)	Shade adjustment (5>8 / 9>13)
<b>3</b>	1,2,3	Return-to-clear time adjustment