 


Clear Water Solenoid Valve - modular system

CWS 7 serie - 721.34M10.01393.24


ICH BV

Plastic solenoid valve high reliable valve.
This valve is NC, single inlet/single outlet.
It is an indirect control electromagnetical valve.
NSF Standard 169, special for food equipment and devices.
Standard seal is EPDM.
OEM version: on request



Specifications


Operating Range	0.2 ~10 bar
Voltage	24Vdc 8W
Coil	Class H IP00
Function	Normally closed (NC)
Orifice	9 mm
Media	Neutral clear water
Fluid temperature	90° C 3 ' On / 5 ' Off
E.D.	25° C 100%
Ambient temperature	60° C max.

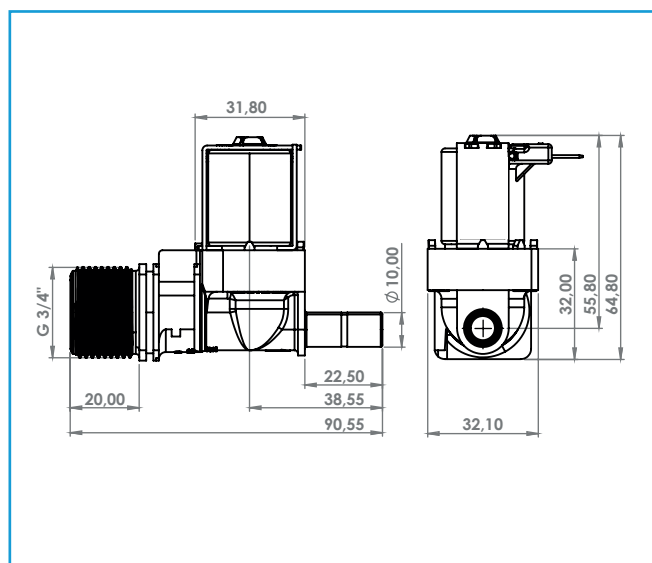


Code	Connection	Body	Seal	Certification
721.34M10.01393.24	3/4" male inlet	PA Plastic	EPDM	NSF
	10mm outlet			WRAS
	for Push-in coupling			Anti water hammering
				NEN-EN_IEC 60730-2-8

Options

Bracket

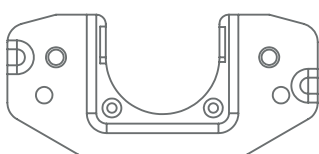

Impeller

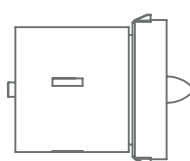

Flow sensor



Inlet flow restrictor



Clear Water Solenoid Valve - modular system

CWS 7 serie

