

EASYPIX.

# BIRDY CAM

BIRD FEEDER



## Digital Video/Photo Box + Bird Feeder

- Enjoy watching birds and other animals without disturbing them
- Automatic Motion Detection
- 3M Detection Range
- 0.8 Sec. Trigger Time
- High Definition Video
- Photos up to 12MP
- Display 1.44"/3.6 cm
- Double Solar Panel
- Built-in Lithium Battery
- Low Power Consumption



### Double Solar Panel

Provide a continuous power supply



## BIRDY CAM + FEEDER

Art. Nr. 10123

EAN 4260041686533

## RESOLUTION

Video	1080p*, 720p, 480p
Photo	3M*, 5M*, 8M*, 12M*

## FEATURES

Housing	Weatherproof
Space for food	For approx. 250g of grain food
Sensor	1.3MP CMOS
Lens	Fixed Focus, F 5.5, f=3.9 mm
PIR Sensor	Automatic Motion Detection
Detection Range	Up to 3M
Trigger Time	0.8 sec.
Display	1.44"/3.6 cm
Recording Modes	Photo / Video / Photo + Video
Video Length	10 sec. / 30 sec. / 1 min. / 3 min.
Photo Burst	3 / 5 / 10 photos
Auto Power Off	Yes
Microphone	Built-in
File Format	AVI, JPG
Interface	USB Type-C
Double Solar Panels	Light intensity: 38000-40000, about 8 hours full charge
Battery	Lithium Battery 1200mAh built-in
Battery Life Time	About 6 hours of continuous video recording
Dimensions, Weight	17.5 x 12.5 x 13 cm, 350g

## EXTERNAL MEMORY

(Not included)  
Compatible with microSD cards up to max. 32 GB




## INCLUDED ACCESSORIES

Bird Camera + Feeder, Water Sink, Nectar Feeder, Strap, Pole Mount, Mount Adaptor, USB Cable, User's Manual




## Unique animal perspectives

Very easy to fill with food and water

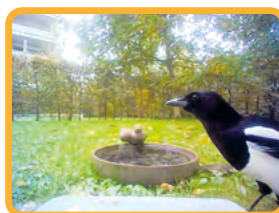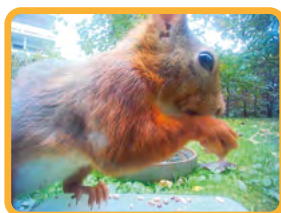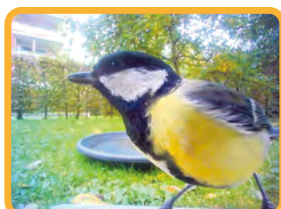

● Original BirdyCam shots

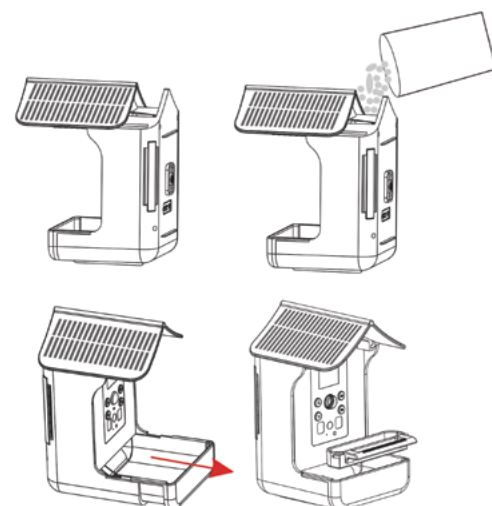

Technical changes and mistakes reserved. \*by interpolation