


Data Sheet

2-Way Battery Connector Splitter Cable, 16AWG, L: 600MM

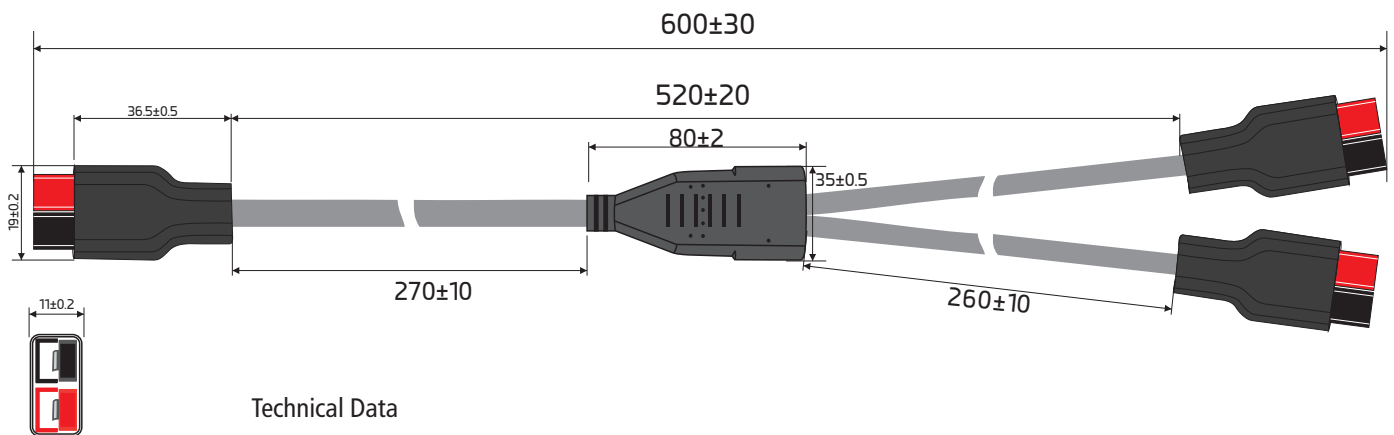

Technical Data

Rated Voltage: 300 V
Rated Current: 20 A max.
Contact Resistance: <12 mΩ
Insulation Resistance: >500 MΩ
Cable Size: AWG 16 / 1.3 mm²
Cable Length: 520 mm / overall 600 mm
Flame Retardant Grade: UL 94V-0
Operating Temperature: -20°C ~ 80°C
Material
Battery Connector
Plastic Cover: PVC, Black
Housing: Polycarbonate (PC)
Terminal Contact: Silver Plated Copper
Solar Cable
Conductor: Bare Copper
Insulation Jacket: PVC / VW-1

