

# PRIME C2



**1000**  
MAX LUMENS

**114**  
METERS THROW

**4.5**  
MONTHS RUNTIME

WHITE, WARM  
LIGHT


 


**RECHARGEABLE**

Magnetic USB charger and battery included

**Dimensions**

Length 104 mm  
Head diameter 24.5 mm  
Weight with battery 105 g

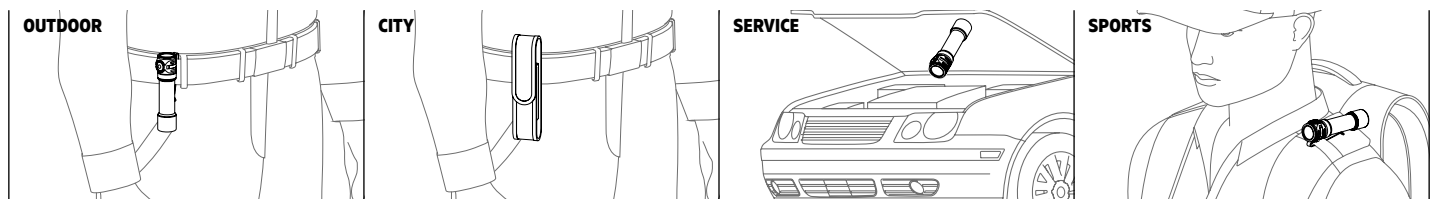

## Every Day Carry light with large hotspot and simple operation

A new model of a classic form Every Day Carry light with wide beam and large hotspot. Prime C2 is a flashlight for those who utilize a basic set of modes in everyday application. Optimal brightness, intuitive operation, as well as included and optional accessories make the new product of the Prime series an indispensable main or additional light source on an evening walk, during overnight camping or at home. A reliable nylon holster allows fixing the

flashlight to the belt and protects the housing from scratches during storage and transportation. Prime C2 can also be placed inside a car and used for malfunction diagnostics or as an additional trunk light: all one needs is to fix the flashlight on a metal surface. In addition to that, due to its compatibility with the original bicycle mount, Prime C2 is installed on any bike for use as a bicycle light.




 2 in 1





### 1 EVERY DAY CARRY LIGHT

Compact design, convenient side button, special matt anti-abrasive finish without rough knurling. Durable nylon holster, robust removable steel clip and strong built-in tail magnet.

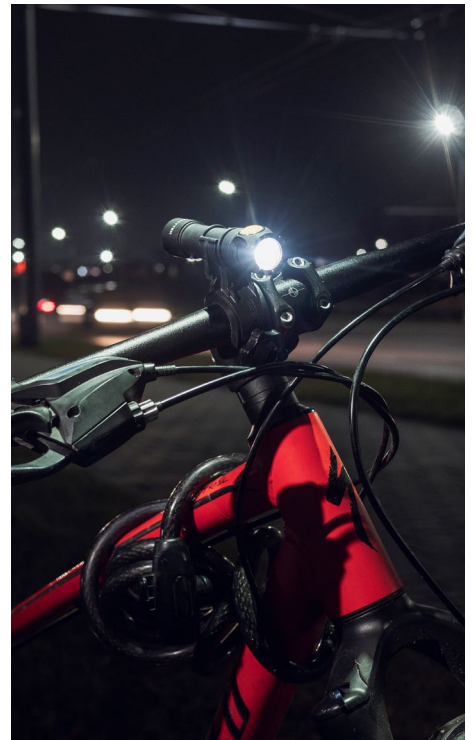

### 2 SPORTS FLASHLIGHT

Body made from durable and lightweight aircraft-grade aluminium, improved shock resistance. Constant light without flickering. Multiple variants of installation, optional accessories for mounting on sporting gear.

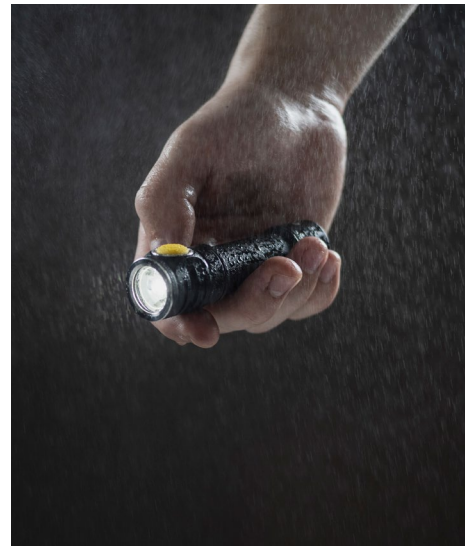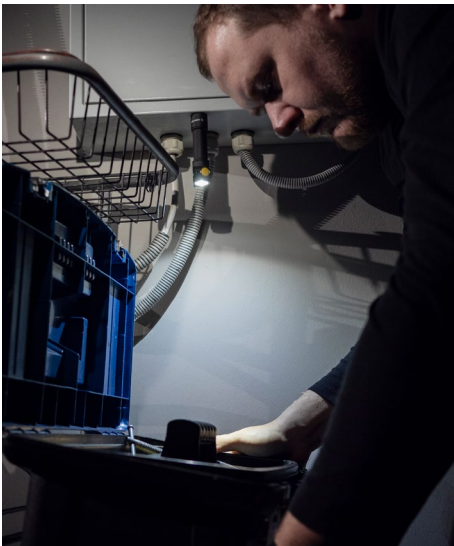


- Possibility to set the timer for automatic switching-off
- Convenient wide beam with large hotspot, fully upgraded optical system, TIR-lens is protected from scratches by tempered glass with anti-reflective coating

- Innovative technology allows using any standard 18650 Li-Ion battery. Full protection against short circuit even in case of contact between magnetic connector and metal objects
- Active real-time temperature control to prevent overheating above +58 °C and warning indication of low battery level

- Total protection from water, dirt and dust in accordance with IP68 standard – flashlight continues to work even after submersion at 10 meters depth. Withstands fallings from up to 10 meters



# ADVANTAGES OF PRIME C2

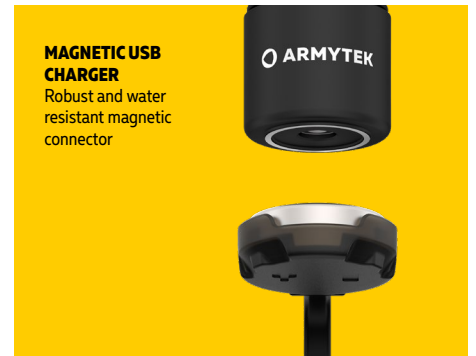

**MAGNETIC USB CHARGER**  
Robust and water resistant magnetic connector

**Large side button:** soft and comfortable pressing

**Innovated electronics:** combination of high brightness and prolonged runtimes

**Simple operation:** 6 modes, easy to use right out of the box

**Steel bezel:** additional protection of the optical system


**Stylish body:** matt anodizing and laconic design

**Active real-time temperature control:** ensures safe and comfortable use. When the temperature becomes close to +58 °C, the brightness decreases, which allows avoiding flashlight and battery overheating, as well as LED degradation. Compliant with European safety standards

**Ready-to-use solution:** 18650 Li-ion 3200 mAh battery and fast magnetic USB charger included

**Intelligent charging algorithm:** safe current to extend battery life. The included 18650 Li-Ion 3200 mAh battery is charged in

 **3 h 20 min**

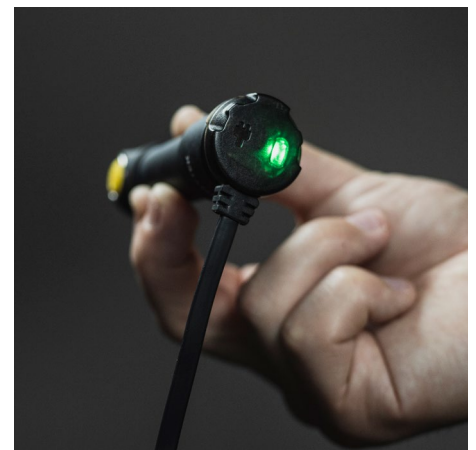

# Well-thought-out set of accessories


Removable stainless steel clip provides reliable mounting on clothing, belt or bag, as well as deep fit on the pocket.

Nylon holster with several fixing options – on a belt of any width, on equipment thanks to durable ring.

Powerful built-in magnet in the tailcap is for attachment to any metal surface.



- 1 - flashlight
- 2 - 18650 Li-Ion battery 3200 mAh
- 3 - fast magnetic USB charger
- 4 - steel clip
- 5 - nylon holster
- 6 - two spare O-rings
- 7 - user manual in eight languages

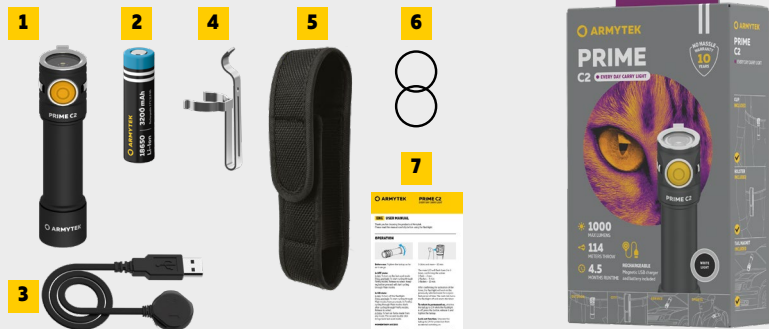

## SPECIFICATIONS

		Prime C2
<b>Optics</b>		TIR
<b>Light output</b>		1000 lm
<b>Beam distance</b>		114 m
<b>Hotspot : Spill</b>		25°:120°
<b>Brightness stabilization type</b>		Digital
<b>Number of modes</b>		6
<b>Modes / Runtimes</b>		<b>Turbo</b> 1000 lm / 4 h (420 lm after 2 min) <b>Main3</b> 360 lm / 4 h 20 min <b>Main2</b> 170 lm / 10 h <b>Main1</b> 40 lm / 47 h <b>Firefly2</b> 2.5 lm / 18 d <b>Firefly1</b> 0.15 lm / 140 d
<b>Power source</b>		1x18650 Li-Ion
<b>Length / head diameter / body diameter</b>		104 mm / 24.5 mm / 20.5 mm
<b>Weight without / with battery</b>		55 g / 105 g
<b>Ingress protection, Submersion and Impact resistance</b>		IP68. Depth up to 10 m for 5 h. Height up to 10 m

► The model is available with White and Warm light. Light output for flashlights with Warm light is about 7% less, beam distance is about 3% less. All the above specifications are test results based on ANSI/PLATO FL 1-2019 Standard. The data may vary due to environment, heat dissipation and other factors.

# BENEFITS OF WORKING WITH ARMYTEK

Armytek is a world famous manufacturer of high-tech flashlights, chargers and accessories. All Armytek products perfectly meet the buyer's requirements. We focus on quality and reliability: smart lineup allows us to thoroughly think through every detail before launching mass production.

## **HIGH PROFIT**

Favorable conditions and flexible prices for bulk orders are ensured by own factories in China.

## **FAST SHIPPING**

Warehouses around the world: the goods are always in stock and ready for shipment. Reduced costs and time of delivery, no additional customs fees required. Lower costs on shippings directly from the factories.

## **EXCEPTIONAL RELIABILITY**

Minimum returns rate – less than 1% (competitors' rate is 5-7%). All products go through quality checking on test stands.

## **LEGENDARY SERVICE**

Full support and cooperation: from placing an order to warranty service. Professional issue management, fast repairs and exchange.

## **NO HASSLE WARRANTY**

Up to 10 years unprecedented warranty.

## **OWN FACTORIES**

Every step of the process is controlled by our European specialists at the factories.

## **DEVELOPMENT**

Head office in Europe. Team of highly qualified specialists from defence, aviation, space and other specialized industries.

## **EXPERIENCE**

Expert in the fields of mechanics, optics and electronics. We specialize in development and manufacturing of flashlights and battery chargers since 2009.

## **COMPONENTS**

Components by world's leading manufacturers. Powerful LEDs, innovative electronics, aircraft-grade aluminium, tempered glass, etc.

## **SMART LINEUP**

Simple process of choosing a product, no bulky catalogs with a lot of similar variants. Only best models for client's needs.

## **NEW PRODUCTS**

Armytek produces innovative and the most technically advanced products in the world.

## **PRIVATE LABEL, OEM/ODM**

Creating new products, modifying our production models and personalizing them according to your needs.

## **MARKETING SUPPORT**

We provide all the necessary promotional materials: leaflets, booklets, catalogs, etc.

## **CLIENTS' NEEDS RESEARCH**

We systematically gather feedback to make sure that our products completely fit clients' needs and requirements.

**Built to exceed**