


WIZARD C2 PRO

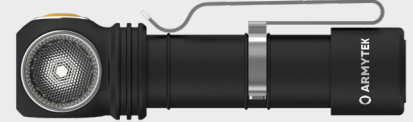

2500
MAX LUMENS






 
131
METERS THROW

6.5
MONTHS RUNTIME

WHITE, WARM
LIGHT

RECHARGEABLE
Magnetic USB charger
and battery included

DIMENSIONS
Length 112 mm
Head diameter 33 mm
Weight with battery 115 g

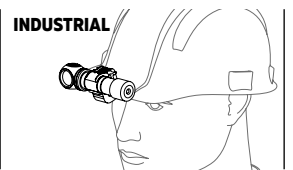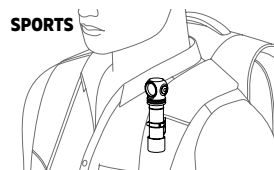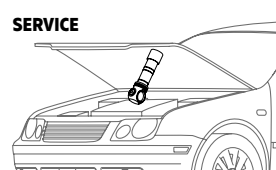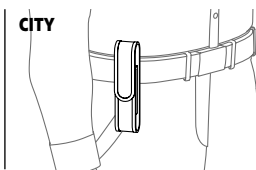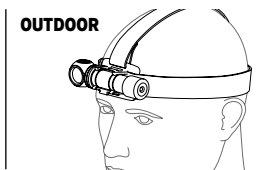


Legendary multi flashlight is now even brighter, more reliable and convenient

Updated version of the legendary Wizard Pro multi flashlight. Wizard C2 Pro is the perfect solution for those who are looking for a multifunctional flashlight for continuous professional and day-to-day use. The model is characterized by incredible brightness and maximum beam distance in the multi flashlight lineup. Charges from any USB power source using magnetic USB cable. The set includes comfortable headmount, clip for attaching to clothes or a backpack,

and durable nylon holster. Powerful magnet in the tailcap allows fixing the flashlight to any metal surface. Wizard C2 Pro is compatible with bicycle mount ABM-01 and AHM series helmet mounts for industrial works and mountaineering. Multifunctional flashlight with a wide and long-throw beam is the choice of runners, fishers, hunters, auto mechanics, industrial workers and other professionals around the world.

3 in 1

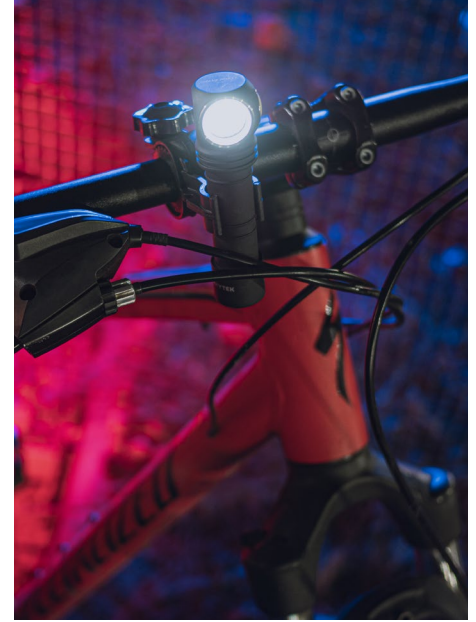

1 HEADLAMP


Simple one-hand operation, reliable head-mount. Solid body without long wires, weak rubber connectors and unnecessary boxes. The flashlight is easily installed, removed and 180° rotatable in the mount. Quick-release silicone ring provides additional fixation.

2 EVERY DAY CARRY LIGHT

Compact design, convenient side button, special matt anti-abrasive finish without rough knurling. Durable nylon holster, robust removable steel clip and strong built-in tail magnet.

3 SPORTS FLASHLIGHT


Body made from durable and lightweight aircraft-grade aluminium, improved shock resistance. New springs for better battery and driver protection, constant light without flickering. Multiple variants of installation, optional accessories for mounting on sporting gear.

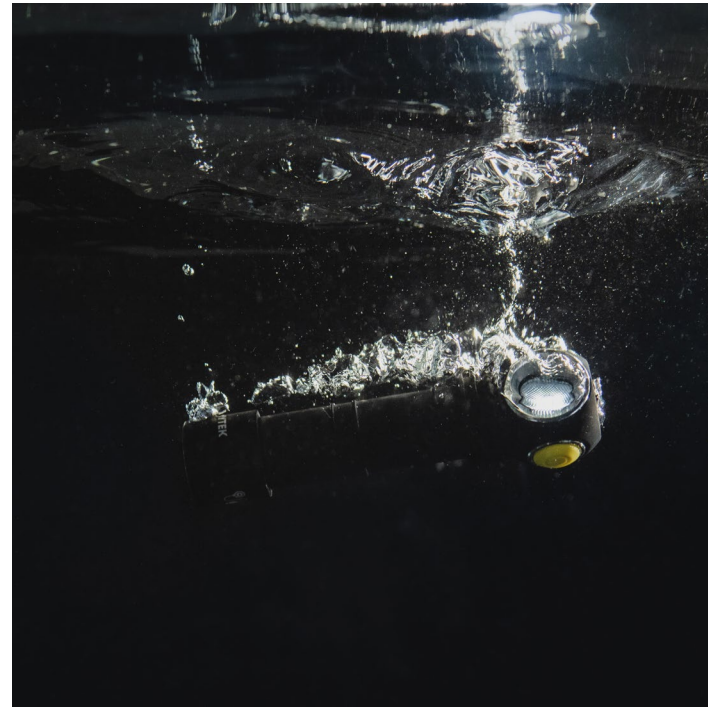

- Powerful electronics provides impressive light output and record runtimes. Constant brightness even at low ambient temperatures and not fully charged battery
- Multicolor temperature, battery level and state indication
- Convenient wide beam of fully upgraded optical system, steel bezel and tempered glass with anti-reflective coating for protection of the TIR-lens

- Innovative technology allows using any standard 18650 Li-Ion battery with 10A discharge current. Full protection against short circuit even in case of contact between magnetic connector and metal objects
- Active real-time temperature control to prevent overheating above +58 °C
- Total protection from water, dirt and dust in accordance with IP68 standard – flashlight continues to work even after submersion at 10 meters depth. Withstands fallings from up to 10 meters

WIZARD C2 PRO FEATURES

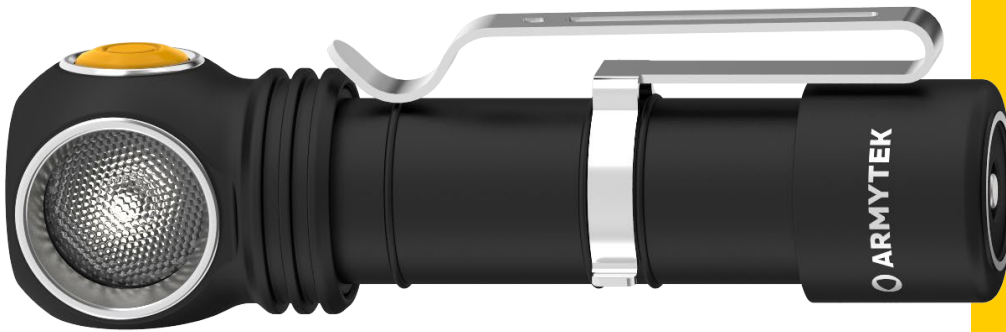

Specially designed optical system and TIR-lens: transmits more lumens, provides greater beam distance with comfortable wide spill

Maximum LED efficiency: impressive for such a compact model brightness of

 **2500**
LUMENS


Thought-out head design: improved heat dissipation and brighter light with more lumens

Large side button: soft and comfortable pressing

Innovated electronics: combination of high brightness and prolonged runtimes

Intelligent charging algorithm: safe current to extend battery life. The included 18650 Li-Ion 3500 mAh battery is charged in

 **3 h 40 min**

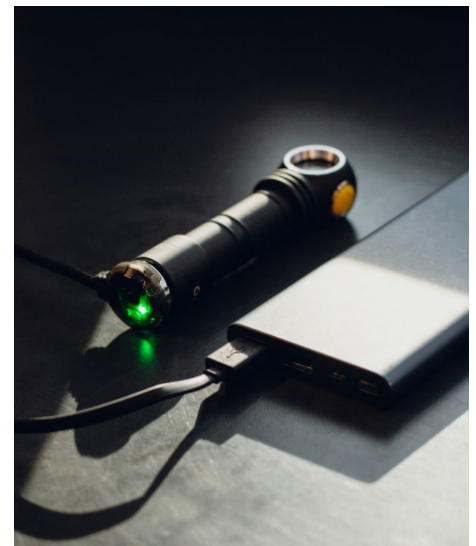

Simple operation by default: easy to use right out of the box (6 modes), possible to switch to professional advanced operation with 12 modes

Improved springs: new springs for better protection of the battery and driver and increased performance efficiency

Active real-time temperature control: ensures safe and comfortable use. When the temperature becomes close to +58 °C, the brightness decreases, which allows avoiding flashlight and battery overheating, as well as LED degradation. Compliant with European safety standards

Steel bezel: additional protection of the optical system

Stylish body: matt anodizing and laconic design


Ready-to-use solution: 18650 Li-Ion 3500 mAh battery and fast magnetic USB charger included

Well-thought-out set of accessories

Comfortable headmount with two soft elastic bands, lightweight holder made from composite material and rubber ring for additional fixation. The bands securely hold the flashlight, do not rub the skin and leave no marks. The flashlight is installed in one motion, the size of the mount is adjustable.



Removable stainless steel clip has two options for installation on the flashlight, provides a reliable mounting on clothing, belt or bag, as well as deep fit on the pocket.

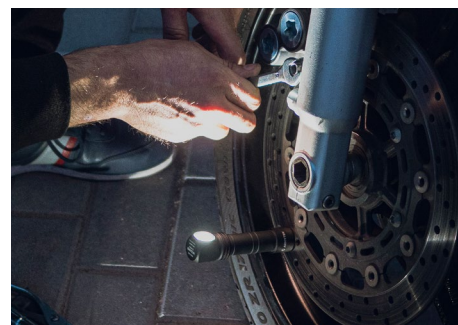

Nylon holster with several fixing options: on a belt of any width, on equipment thanks to durable ring.

Powerful built-in magnet in the tailcap is for attachment to any metal surface.

- 1 - flashlight
- 2 - 18650 Li-Ion battery 3500 mAh
- 3 - fast magnetic USB charger
- 4 - headmount
- 5 - steel clip
- 6 - nylon holster
- 7 - two spare O-rings
- 8 - user manual in eight languages

SPECIFICATIONS

		Wizard C2 Pro
Optics		TIR
Light output		2500 lm
Beam distance		131 m
Hotspot : Spill		70°:120°
Brightness stabilization type		Full
Number of modes		6 simple operation by default / 12 advanced operation
Modes / Runtimes	Turbo3	2500 lm / 2 h 40 min (650 lm after 30 sec)
	Turbo2	1750 lm / 2 h 45 min (650 lm after 2 min)
	Turbo1	870 lm / 2 h 50 min (650 lm after 9 min)
	Main3	370 lm / 5 h 15 min
	Main2	160 lm / 12 h 15 min
	Main1	45 lm / 43 h
	Firefly3	6 lm / 12 d
	Firefly2	1.5 lm / 40 d
	Firefly1	0.15 lm / 200 d
	Strobe3	2500 lm / 10 Hz / 5 h 45 min (650 lm after 100 sec)
Strobe2	2500 lm / 1 Hz / 12 h (650 lm after 9 min)	
Strobe1	160 lm / 1 Hz / 55 h	
Power source		1x18650 Li-Ion
Length / head diameter / body diameter		112 mm / 33 mm / 20.4 mm
Weight without / with battery		65 g / 115 g
Ingress protection, Submersion and Impact resistance		IP68. Depth up to 10 m for 5 h. Height up to 10 m

► The model is available with White and Warm light. Light output for flashlights with Warm light is about 7% less, beam distance is about 3% less. All the above specifications are test results based on ANSI/PLATO FL 1-2019 Standard. The data may vary due to environment, heat dissipation and other factors.

BENEFITS OF WORKING WITH ARMYTEK

Armytek is a world famous manufacturer of high-tech flashlights, chargers and accessories. All Armytek products perfectly meet the buyer's requirements. We focus on quality and reliability: smart lineup allows us to thoroughly think through every detail before launching mass production.

HIGH PROFIT

Favorable conditions and flexible prices for bulk orders are ensured by own factories in China.

FAST SHIPPING

Warehouses around the world: the goods are always in stock and ready for shipment. Reduced costs and time of delivery, no additional customs fees required. Lower costs on shippings directly from the factories.

EXCEPTIONAL RELIABILITY

Minimum returns rate – less than 1% (competitors' rate is 5-7%). All products go through quality checking on test stands.

LEGENDARY SERVICE

Full support and cooperation: from placing an order to warranty service. Professional issue management, fast repairs and exchange.

NO HASSLE WARRANTY

Up to 10 years unprecedented warranty.

OWN FACTORIES

Every step of the process is controlled by our European specialists at the factories.

DEVELOPMENT

Head office in Europe. Team of highly qualified specialists from defence, aviation, space and other specialized industries.

EXPERIENCE

Expert in the fields of mechanics, optics and electronics. We specialize in development and manufacturing of flashlights and battery chargers since 2009.

COMPONENTS

Components by world's leading manufacturers. Powerful LEDs, innovative electronics, aircraft-grade aluminium, tempered glass, etc.

SMART LINEUP

Simple process of choosing a product, no bulky catalogs with a lot of similar variants. Only best models for client's needs.

NEW PRODUCTS

Armytek produces innovative and the most technically advanced products in the world.

PRIVATE LABEL, OEM/ODM

Creating new products, modifying our production models and personalizing them according to your needs.

MARKETING SUPPORT

We provide all the necessary promotional materials: leaflets, booklets, catalogs, etc.

CLIENTS' NEEDS RESEARCH

We systematically gather feedback to make sure that our products completely fit clients' needs and requirements.

Built to exceed