


# WIZARD C2 PRO MAX

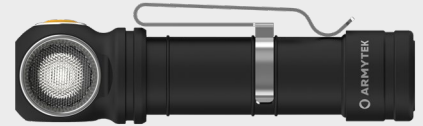

**4000**  
MAX LUMENS

**114**  
METERS THROW

**2**  
MONTHS RUNTIME

WHITE, WARM  
LIGHT





**RECHARGEABLE**

Magnetic USB charger  
and battery included

**DIMENSIONS**

 Length 121.5 mm  
Head diameter 34.4 mm  
Weight with battery 149 g

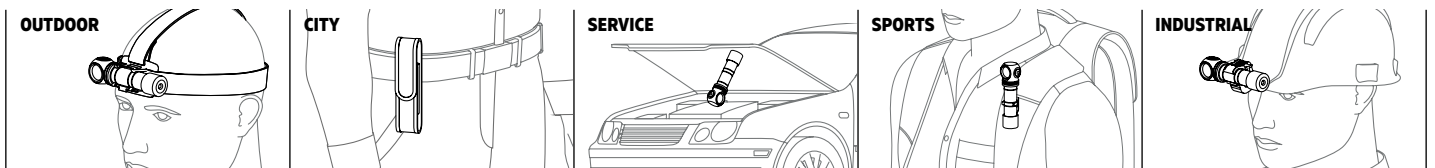

Flagship product  
in the multi flashlight  
lineup – brightness  
like never before


Flashlight for those who need not just bright, but astonishing light. Wizard C2 Pro Max is the newest model of the demanded all over the

world multifunctional Armytek Wizard lineup with record light output of 4000 lumens. The 3 in 1 multi flashlight for outdoor activities, hobbies and work is comparable in power to a spotlight.

The main advantages of the flashlight are wide beam angles 110°:150° and impressive for such a compact model brightness. Combined with extended runtimes provided by the larger capacity 21700 Li-Ion battery, these features make the use as effective as possible. Thanks to the battery adapter in the set,

the flashlight also works on the common 18650 Li-Ion power supply. Headmount, clip, holster, magnet in the tailcap and optional bike mount ABM-01 provide various attachment options. Wizard C2 Pro Max is also compatible with original hard hat mounts for industrial works and mountaineering. Wide flood light of the flashlight is optimal both for operating at a close distance and for highlighting large spaces. Suitable for service and industrial works, outdoor activities or sports.

**3 in 1**

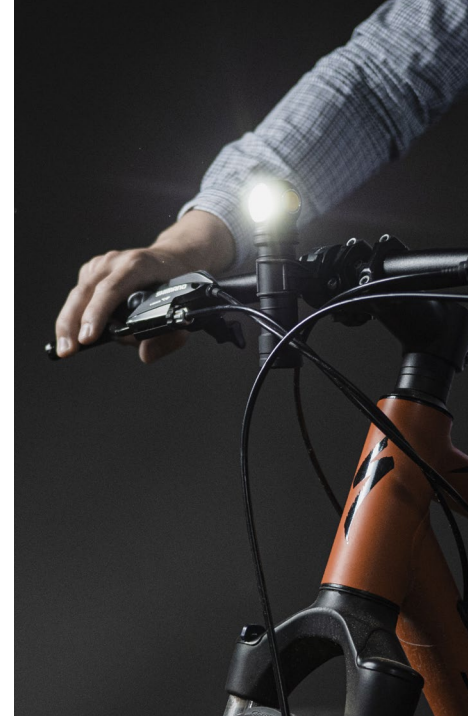

**1 HEADLAMP**


Simple one-hand operation, reliable head-mount. Solid body without long wires, weak rubber connectors and unnecessary boxes. The flashlight is easily installed, removed and 180° rotatable in the mount. Quick-release silicone ring provides additional fixation.

**2 EVERY DAY CARRY LIGHT**

Compact design, convenient side button, special matt anti-abrasive finish without rough knurling. Durable nylon holster, robust removable steel clip and strong built-in tail magnet.

**3 SPORTS FLASHLIGHT**

Body made from durable and lightweight aircraft-grade aluminium, improved shock resistance. New springs for better battery and driver protection, constant light without flickering. Multiple variants of installation, optional accessories for mounting on sporting gear.

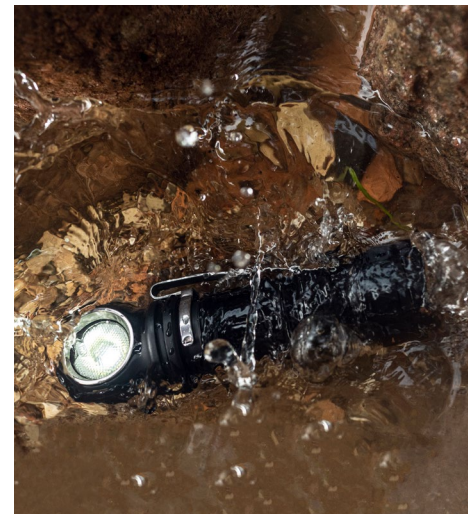


- New generation electronics provides impressive light output of 4000 lumens. Constant brightness even at low ambient temperatures and not fully charged battery
- Multicolor temperature, battery level and state indication

- Convenient wide beam of fully upgraded optical system, steel bezel and tempered glass with anti-reflective coating for protection of the TIR-lens
- Innovative technology allows using any standard 21700 Li-Ion or 18650 Li-Ion

battery with 15A discharge current. Full protection against short circuit even in case of contact between magnetic connector and metal objects

- Active real-time temperature control to prevent overheating above +58 °C
- Total protection from water, dirt and dust in accordance with IP68 standard – flashlight continues to work even after submersion at 10 meters depth. Withstands fallings from up to 10 meters

# WIZARD C2 PRO MAX NEXT GENERATION FLASHLIGHT FEATURES

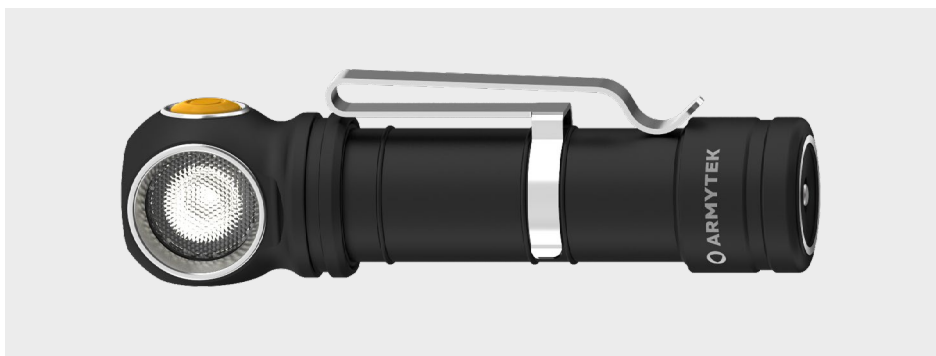

**Specially designed optical system and TIR-lens:** transmits more lumens, provides comfortable wide beam with 150° spill.

**Maximum LED efficiency:** wide new generation LED ensures better light efficiency with impressive output of

 **4000**  
LUMENS


**Thought-out head design:** improved heat dissipation and brighter light with more lumens

**Large side button:** soft and comfortable pressing

**Innovated electronics:** combination of high brightness and prolonged runtimes

**Intelligent charging algorithm:** safe current to extend battery life. The included 21700 Li-Ion 5000 mAh battery is charged in

 **5 h 20 min**

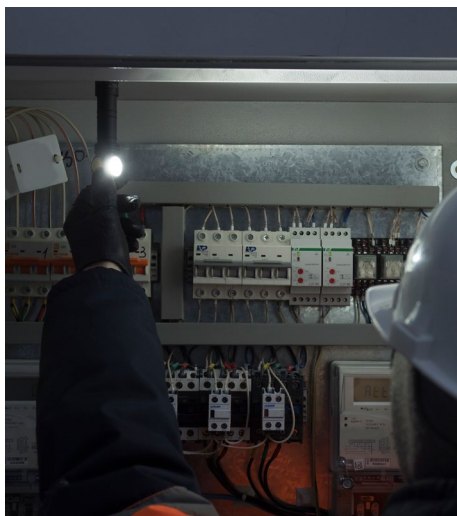

**Simple operation by default:** easy to use right out of the box (6 modes), possible to switch to professional advanced operation with 10 modes

**Improved springs:** new springs for better protection of the battery and driver and increased performance efficiency

**Active real-time temperature control:** ensures safe and comfortable use. When the temperature becomes close to +58 °C, the brightness decreases, which allows avoiding flashlight and battery overheating, as well as LED degradation. Compliant with European safety standards


**Steel bezel:** additional protection of the optical system

**Stylish body:** matt anodizing and laconic design

**Ready-to-use solution:** 21700 Li-Ion 5000 mAh battery, battery adapter for use of any 18650 Li-Ion battery and fast magnetic USB charger included

# Well-thought-out set of accessories

Comfortable headmount with two soft elastic bands, lightweight holder made from composite material and rubber ring for additional fixation. The bands securely hold the flashlight, do not rub the skin and leave no marks. The flashlight is installed in one motion, the size of the mount is adjustable.

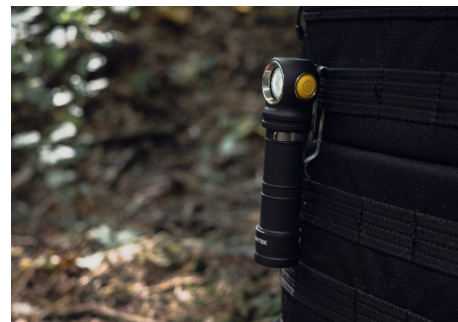

Removable stainless steel clip has two options for installation on the flashlight, provides a reliable mounting on clothing, belt or bag, as well as deep fit on the pocket.

Nylon holster with several fixing options: on a belt of any width, on equipment thanks to durable ring.



Powerful built-in magnet in the tailcap is for attachment to any metal surface.

- 1 - flashlight
- 2 - 21700 Li-Ion battery 5000 mAh
- 3 - 18650 battery adapter
- 4 - fast magnetic USB charger
- 5 - headmount
- 6 - steel clip
- 7 - nylon holster
- 8 - two spare O-rings
- 9 - user manual in eight languages

## SPECIFICATIONS

		Wizard C2 Pro Max
<b>Optics</b>		TIR
<b>Light output</b>		4000 lm
<b>Beam distance</b>		114 m
<b>Hotspot : Spill</b>		110°:150°
<b>Brightness stabilization type</b>		Full
<b>Number of modes</b>		6 simple operation by default / 10 advanced operation
<b>Modes / Runtimes</b>	<b>Turbo2</b>	4000 lm / 3 h 15 min (900 lm after 50 sec)
	<b>Turbo1</b>	1300 lm / 3 h 20 min (900 lm after 12 min)
	<b>Main3</b>	450 lm / 7 h
	<b>Main2</b>	150 lm / 21 h
	<b>Main1</b>	45 lm / 64 h
	<b>Firefly2</b>	7 lm / 10 d
	<b>Firefly1</b>	0.6 lm / 62 d
	<b>Strobe3</b>	4000 lm/10 Hz/6 h 50 min (900 lm after 2 min)
	<b>Strobe2</b>	4000 lm/1 Hz/14 h (900 lm after 10 min)
<b>Strobe1</b>	150 lm/1 Hz/90 h	
<b>Power source</b>		1x21700 Li-Ion, 1x18650 Li-Ion
<b>Length / head diameter / body diameter</b>		121.5 mm / 34.4 mm / 23.6 mm
<b>Weight without / with battery</b>		79 g / 149 g
<b>Ingress protection, Submersion and Impact resistance</b>		IP68. Depth up to 10 m for 5 h. Height up to 10 m

► The model is available with White and Warm light. Light output for flashlights with Warm light is about 7% less, beam distance is about 3% less. All the above specifications are test results based on ANSI/PLATO FL 1-2019 Standard. The data may vary due to environment, heat dissipation and other factors.

# BENEFITS OF WORKING WITH ARMYTEK

Armytek is a world famous manufacturer of high-tech flashlights, chargers and accessories. All Armytek products perfectly meet the buyer's requirements. We focus on quality and reliability: smart lineup allows us to thoroughly think through every detail before launching mass production.

## **HIGH PROFIT**

Favorable conditions and flexible prices for bulk orders are ensured by own factories in China.

## **FAST SHIPPING**

Warehouses around the world: the goods are always in stock and ready for shipment. Reduced costs and time of delivery, no additional customs fees required. Lower costs on shippings directly from the factories.

## **EXCEPTIONAL RELIABILITY**

Minimum returns rate – less than 1% (competitors' rate is 5-7%). All products go through quality checking on test stands.

## **LEGENDARY SERVICE**

Full support and cooperation: from placing an order to warranty service. Professional issue management, fast repairs and exchange.

## **NO HASSLE WARRANTY**

Up to 10 years unprecedented warranty.

## **OWN FACTORIES**

Every step of the process is controlled by our European specialists at the factories.

## **DEVELOPMENT**

Head office in Europe. Team of highly qualified specialists from defence, aviation, space and other specialized industries.

## **EXPERIENCE**

Expert in the fields of mechanics, optics and electronics. We specialize in development and manufacturing of flashlights and battery chargers since 2009.

## **COMPONENTS**

Components by world's leading manufacturers. Powerful LEDs, innovative electronics, aircraft-grade aluminium, tempered glass, etc.

## **SMART LINEUP**

Simple process of choosing a product, no bulky catalogs with a lot of similar variants. Only best models for client's needs.

## **NEW PRODUCTS**

Armytek produces innovative and the most technically advanced products in the world.

## **PRIVATE LABEL, OEM/ODM**

Creating new products, modifying our production models and personalizing them according to your needs.

## **MARKETING SUPPORT**

We provide all the necessary promotional materials: leaflets, booklets, catalogs, etc.

## **CLIENTS' NEEDS RESEARCH**

We systematically gather feedback to make sure that our products completely fit clients' needs and requirements.

**Built to exceed**