


4G Mobile WiFi 3 E5783 Specification

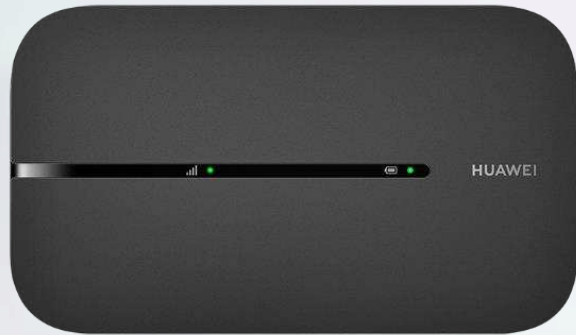

■ Highlights

- Zero Touch, Plug & Play
- LTE Cat7, 300Mbps DL | 100Mbps UL
- WiFi 802.11ac/n , up to 32users access simultaneously
- HUAWEI HomeSec™ Network Protection
- HUAWEI AI Life APP , easy manager the device

Form Factor	Size: 108*62*15.6mm
Speed	LTE Cat7 DL/UL 2CC FDD-LTE: 300Mbps(DL), 100Mbps(UL) TDD-LTE: 220Mbps(DL), 20Mbps(UL) DL 64QAM, UL 16QAM
Band	E5783-230a LTE: B1/3/5/7/8/20/28/32/38/40/41 UMTS: B1/5/8 No GSM UL:3C/7C/38C/40C/41C DL:1C/3C/7C/38C/40C/41C/3A-3A/41A-41A/1A-3A/1A-5A/1A-7A/1A-8A/1A-20A/1A-28A/3A-5A/3A-7A/3A-8A(B8 only SCC)/3A-20A/3A-28A/7A-8A(B8 only SCC)/7A-20A/7A-28A/8A-38A(B38 only SCC)/20A-32A(B32 only SCC)/20A-38A
Basic Feature	Battery Capacity : 1500mAh, Working time:6h
	Display : LED lights, 1*Signal, 1*Battery
	1*Micro USB, 1*SIM card slot (3FF)
	1*Power KEY/1*Reset KEY
	Accessories : 17cm USB charging line , 5V/1A charger (optional)
WiFi	802.11 b/g/n 2*2 MIMO 2.4GHz & 802.11a/n/ac 2*2 MIMO 5GHz , Support 32 user