


4G CPE 3 B535 Specification

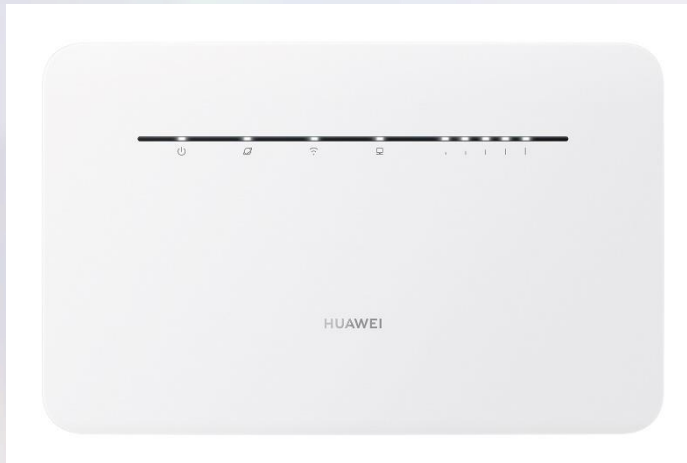

■ Highlights

- LTE Cat7, 300Mbps DL | 100Mbps UL
- WiFi 802.11ac/n , up to 64users access simultaneously
- WiFi AX1300 Dual Band Auto-Selection, always keep WiFi best performance
- HarmonyOS Mesh+ , one-name WiFi, seamless roaming
- HUAWEI AI Life APP , manage your home network effortlessly

Form Factor	Size: 219*138*25.6mm
Speed	LTE Cat7 DL/UL 2CC FDD-LTE: 300Mbps(DL), 100Mbps(UL) TDD-LTE: 220Mbps(DL), 20Mbps(UL)
Band	B535-232a LTE: B1/3/7/8/20/28/32/38 UMTS: B1/8 No GSM UL:3C/7C/38C DL:1C/3C/7C/38C/3A-3A/1A-3A/1A-7A/1A-8A/1A-20A/1A-28A/3A-7A/3A-8A(B8 only SCC)/3A-20A/3A-28A/7A-8A(B8 only SCC)/7A-20A/7A-28A/8A-32A(B32 only SCC)/8A-38A(B38 only SCC)/20A-32A(B32 only SCC)/20A-38A/28A-38A
Interface	4*RJ-45 for data, GE(1 LAN/WAN+3 LAN)
	2*SMA external antenna interface for LTE
	1*SIM card slot (4FF), 1*power interface
	1*Hi(WPS) KEY/1*Reset KEY/1*Power KEY
WiFi	802.11 b/g/n 2*2 MIMO 2.4GHz & 802.11a/n/ac 2*2 MIMO 5GHz , 2.4GHz &5GHz DBDC
Power	AC/DC: AC: 100 V ~ 240 V; DC: 12 V, 1 A