


Data Sheet - TRU Components

BN: 3062650, 3062651, 3062652, 3062653, 3062654, 3062655, 3062656

Last updated: 10 April 2024

NdFeB-Magnet Disc N35SH with countersink hole (2 pcs pair)

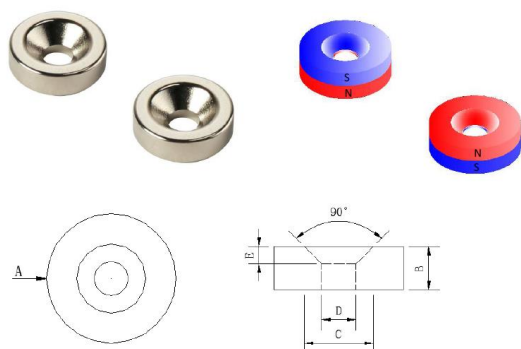

Technical Data:

BN	Outer Ø (A)	Height (B)	Countersink	Head Ø (C)	Base Screw Ø (D)	Head Height (E)
3062650	10 mm	3 mm	M3	6 mm	3 mm	1.5 mm
3062651	10 mm	5 mm	M3	6 mm	3 mm	2 mm
3062652	15 mm	3 mm	M4	8 mm	4 mm	2 mm
3062653	15 mm	5 mm	M4	8 mm	4 mm	2 mm
3062654	20 mm	5 mm	M4	8 mm	4 mm	2 mm
3062655	25 mm	3 mm	M5	10 mm	5 mm	2.5 mm
3062656	25 mm	5 mm	M5	10 mm	5 mm	2.5 mm

Grade: N35SH

Remanence Br: 11.8 to 12.4 kGs

Coercivity bHc: ≥11.0 kOe

Intrinsic Coercivity iHc: ≥20 kOe

Max Energy Product BHmax: 33 to 37 MGOe

Operating Temperature: max. 150°C

Tolerance: ±0.1mm

Finishing: NiCuNi