





Data Sheet - TRU Components

BN: 3062657, 3062659, 3062661

Last updated: 10 April 2024

NdFeB-Magnet Cylinder N35SH

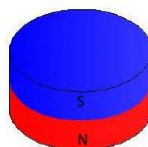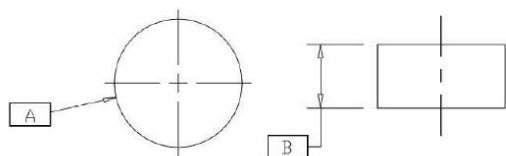

Technical Data:

BN	Ø (A)	Height (B)
3062657	5 mm	2 mm
3062659	10 mm	5 mm
3062661	20 mm	10 mm

Grade: N35SH

Remanence Br: 11.8 to 12.4 kGs

Coercivity bHc: ≥ 11.0 kOe

Intrinsic Coercivity iHc: ≥ 20 kOe

Max Energy Product BHmax: 33 to 37 MGOe

Operating Temperature: max. 150°C

Tolerance: ± 0.1 mm

Finishing: NiCuNi