





Data Sheet - TRU Components

BN: 3062658, 3062660

Last updated: 10 April 2024

NdFeB-Magnet Cylinder N45SH

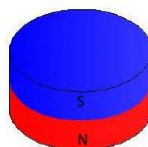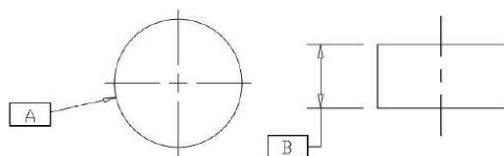

Technical Data:

BN	Ø (A)	Height (B)
3062658	5 mm	2 mm
3062660	10 mm	5 mm

Grade: N45SH

Remanence Br: 13.2 to 13.4 kGs

Coercivity bHc: ≥ 12.5 kOe

Intrinsic Coercivity iHc: ≥ 20 kOe

Max Energy Product BHmax: 42 to 44 MGOe

Operating Temperature: max. 150°C

Tolerance: ± 0.1 mm

Finishing: NiCuNi