




Data Sheet - TRU Components

BN: 3062662, 3062663

Last updated: 10 April 2024

NdFeB-Magnet Rectangular N35SH with 2 Countersink Hole (2 pcs pair)

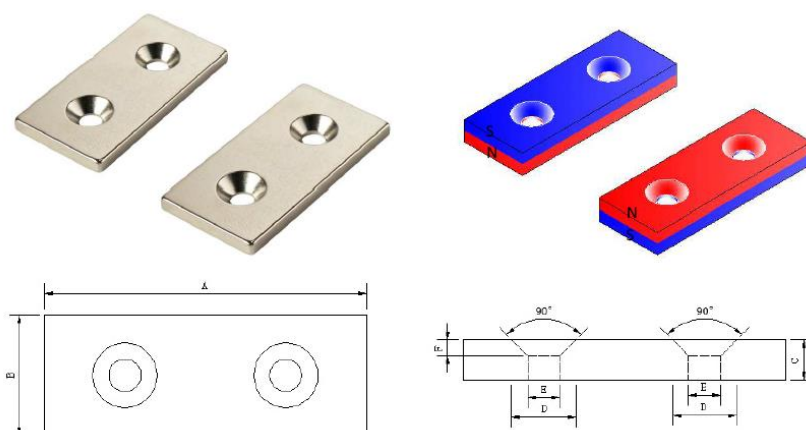

Technical Data:

BN	Length (A)	Width (B)	Height (C)	Countersink	Head Ø (D)	Base ScrewØ (E)	Head Height (F)
3062662	40 mm	15 mm	3 mm	M4 x 2	8 mm	4 mm	2 mm
3062663	40 mm	20 mm	5 mm	M4 x 2	8 mm	4 mm	2 mm

Grade: N35SH

Remanence Br: 11.8 to 12.4 kGs

Coercivity bHc: ≥11.0 kOe

Intrinsic Coercivity iHc: ≥20 kOe

Max Energy Product BHmax: 33 to 37 MGOe

Operating Temperature: max. 150°C

Tolerance: ±0.1mm

Finishing: NiCuNi