





SYNCHRONOUS GEARMOTOR SP SERIES

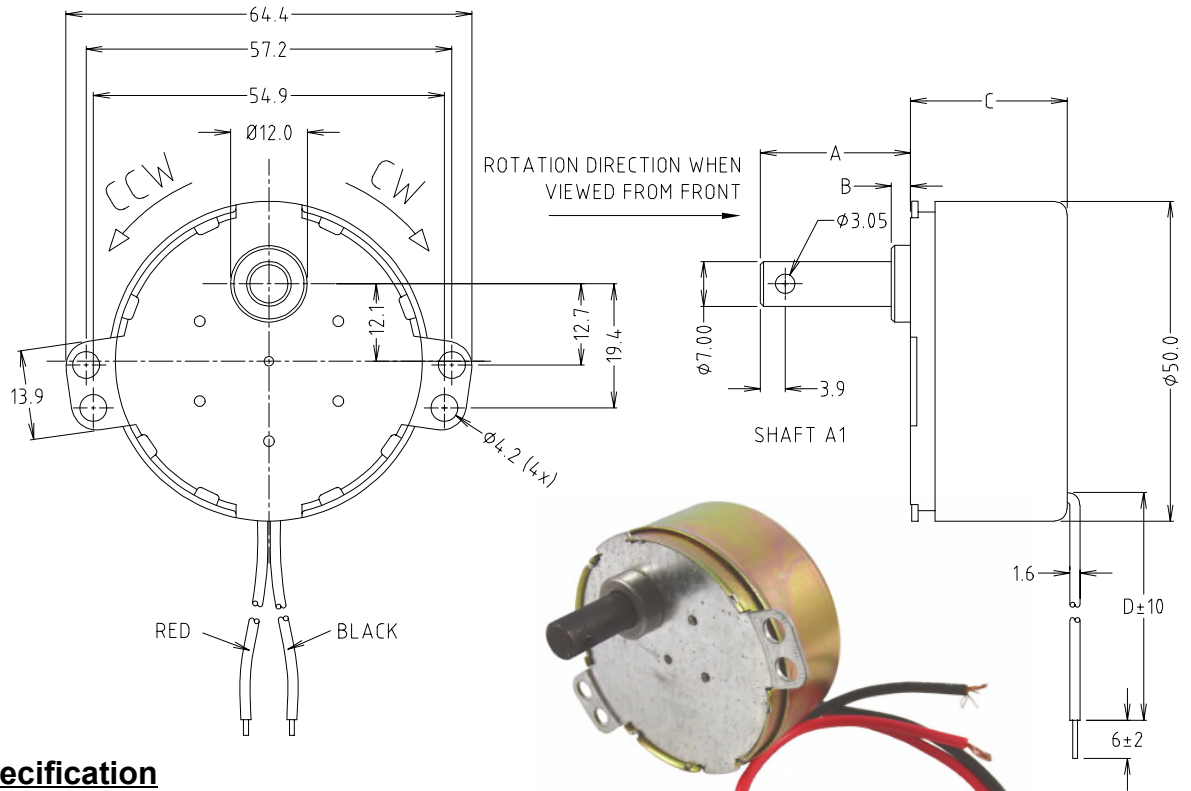

Specification

Power: 4W
 Protection Rating: IP50
 Operating Temperature: -20°...+80°C
 Operating Voltage: 220-240 VAC
 Operating Frequency: 50/60Hz
 Connection: Stranded wires 0.2m
 Housing: 64.4mm.
 Shaft Ø: 7mm.
 RoHS Compliant.

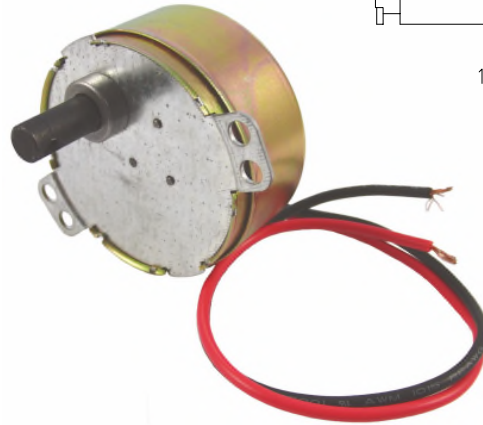

Part No. **FMJ201FB1** Synch Gear motor SP3 Rotation: CW

Speed	2.5/3	R.P.M.
Stall Torque	7.0	kgf-cm

Part No. **FMJ201FJ1** Synch Gear motor SP36 Rotation: CW

Speed	30/36	R.P.M.
Stall Torque	0.6	kgf-cm

Part No. **FMJ201FJ2** Synch Gear motor SP36 Rotation: CCW

Speed	30/36	R.P.M.
Stall Torque	0.6	kgf-cm