





Data Sheet - TRU Components

BN: 3065021

Last updated: 03 April 2024

NdFeB-Magnet Rectangular N35M, 20x19x4 mm

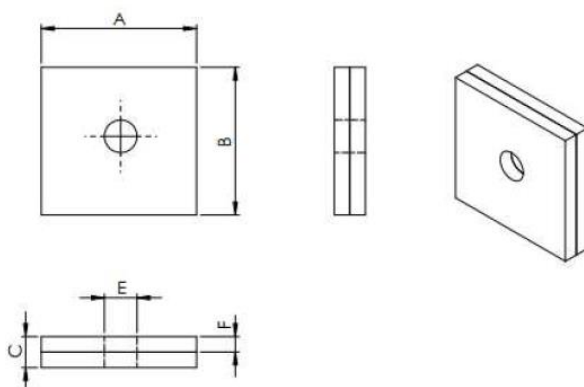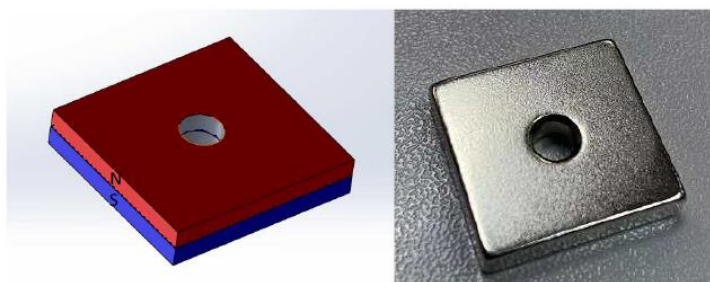

Technical Data:

Length (A)	Width (B)	Height (C)	Base Screw Ø (E)	Head Height (F)
20 mm	19 mm	4 mm	4.2 mm	2 mm

Grade: N35M

Remanence Br: 11.8 to 12.4 kGs

Coercivity bHc: ≥ 10.9 kOe

Intrinsic Coercivity iHc: ≥ 14 kOe

Max Energy Product BHmax: 33 to 37 MGOe

Operating Temperature: max. 100°C

Tolerance: ± 0.1 mm

Finishing: NiCuNi