




Data Sheet - TRU Components

BN: 3065022, 3065023, 3065024

Last updated: 03 April 2024

NdFeB-Magnet Rectangular N38SH

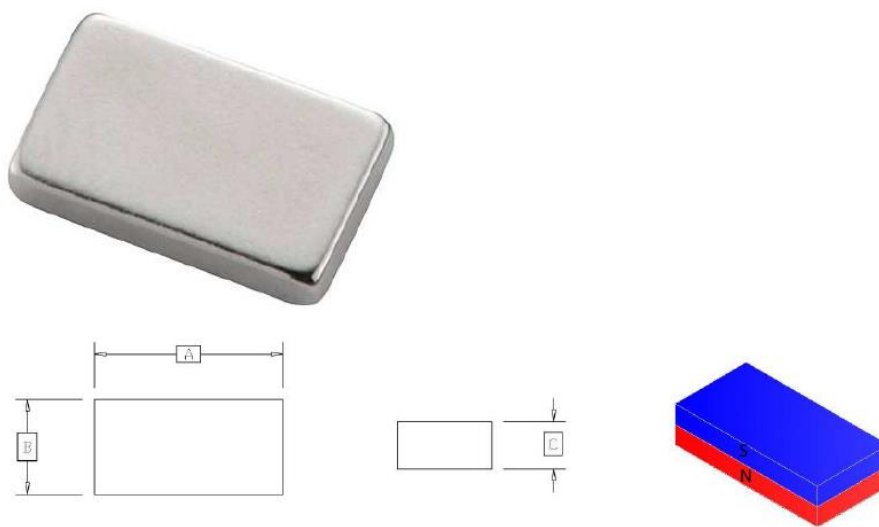

Technical Data:

BN	Length (A)	Width (B)	Height (C)
3065022	20 mm	6 mm	2 mm
3065023	10 mm	6 mm	2 mm
3065024	25 mm	6 mm	2 mm

Grade: N38SH

Remanence Br: 12.3 to 12.6 kGs

Coercivity bHc: ≥ 11.4 kOe

Intrinsic Coercivity iHc: ≥ 20 kOe

Max Energy Product BHmax: 36 to 39 MGOe

Operating Temperature: max. 150°C

Tolerance: ± 0.1 mm

Finishing: NiCuNi