






Data Sheet - TRU Components

BN: 3065025

Last updated: 03 April 2024

NdFeB-Magnet Ring N35M, dia. 13 mm

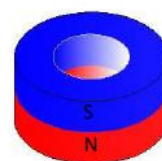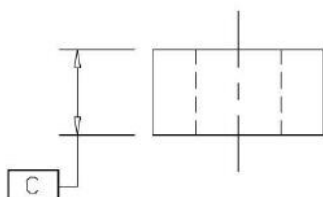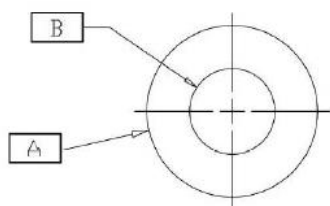

Technical Data:

Outer Ø(A)	Inner Ø (B)	Height (C)
13 mm	4.2 mm	6 mm

Grade: N35M

Remanence Br: 11.8 to 12.4 kGs

Coercivity bHc: ≥ 10.9 kOe

Intrinsic Coercivity iHc: ≥ 14 kOe

Max Energy Product BHmax: 33 to 37 MGOe

Operating Temperature: max. 100°C

Tolerance: ± 0.1 mm

Finishing: NiCuNi