


Length

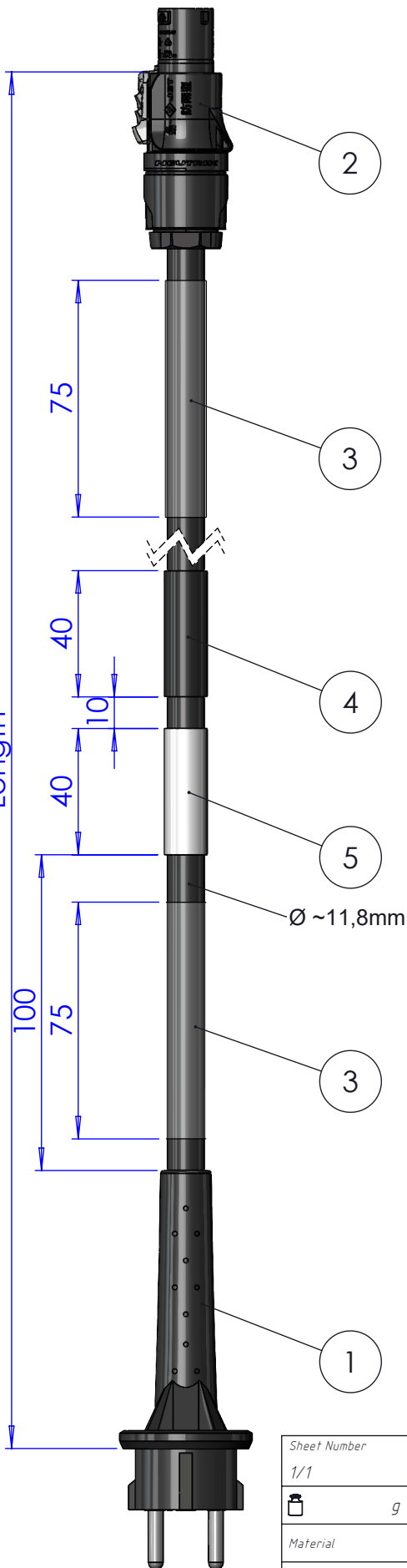

Rubber cable H07RN-F3G2,5 black (L+N+PE)
terminated with:

- NEUTRIK powerCON TRUE1 TOP female connectors
- Schuko "E+F" male

- protection class: IP44
- max. current: 16A
- nominal voltage: 250V~
- operating temperatur: -25°C bis +55°C

Transperent shrink tube loose.
Unshrunked for customized self-labeling before shrinking.

The powerCON TRUE1 TOP is a connector with breaking capacity (CBC), i.e. it can be connected or disconnected under load or live.
(acc. IEC 60320-1 / DIN EN 60320-1 / VDE 0625-1)

Description	Stock-Code	Protection class	Max. current	Length	Weight
NKPH2-MFA1-M0015 1,5 m 3x2,5 mm² H07RN Schuko "E+F" (m) powerCON TRUE1 (f)	1027577	IP44	16A	1,5 m	0,52 kg

No.	Part	Qty.
1	Rubber cable H07RN-F3G2.5 with molded connector CEE 7 Typ E+F	1
2	NEUTRIK NAC3FX-W-TOP-L	1
3	Shrink Tube Ø 12,0 -> 3,0 / unshrunked	2
4	Shrinking tube / CX adress CE+WEE	1
5	Shrinking tube / nameplate	1

Note: cables < 2m only 1x shrink tube, cables >= 2m 2x shrink tubes

Sheet Number 1/1	Projection 	Scale 1:2	Format A4	Tolerancing ISO 2768-	
g	cm ²	cm ³	Created	HeBo	21.12.2021
Material			Modified	HeBo	10.06.2022
Material addition			Approved	DiRo	10.06.2022
Description NKPH2-MFA1 NEUTRIK powerCON TRUE1 to Moulded CEE Plug Cables			ECN Number		
			Status FOR FINAL		
NEUTRIK		3D Model ID	Document ID		Revision 03