
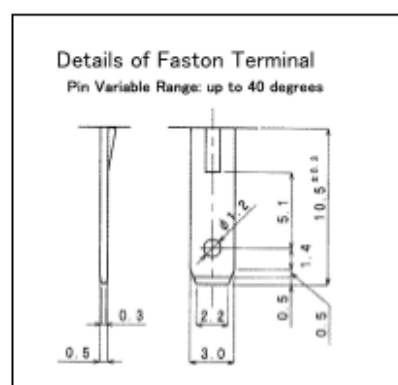
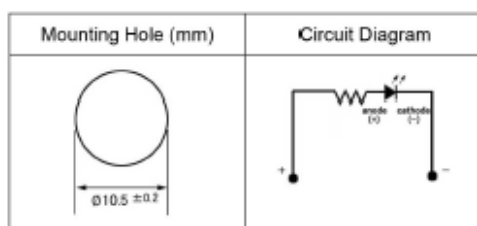


Data Sheet - TRU Components

BN: 3088862

Last updated: 28 March 2024

Indicator Light dia.10 mm, Red LED, Black Metal, 12V DC

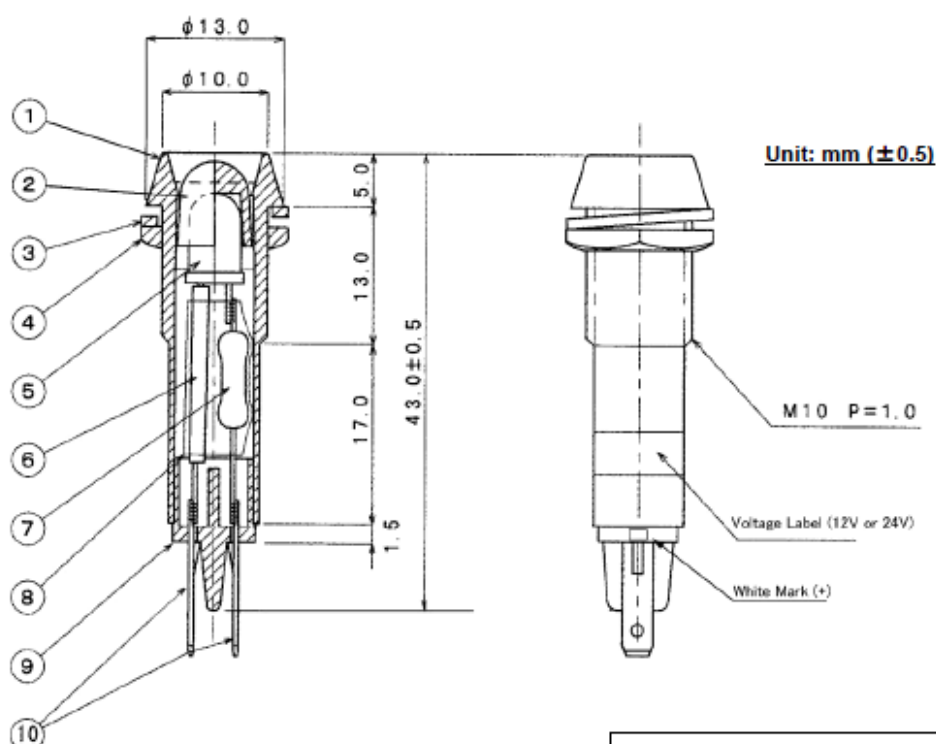

Name of Part	Material		
① Body (Black)	BSBM2		
② Lens	Polycarbonate		
③ Spring Washer	SWP		
④ Hex. Nut	BSBM2		
⑤ LED	Red	DATA	
⑥ Insulation Tube	Irrax Tube A	Voltage	DC12V, DC24V
⑦ Insulation Resistor	1W 1.2k Ω	Dielectric strength	AC 1,000 V / minute
⑧ Insulation Tube	Sumi Tube C	Insulation Resistance	DC 500 V 100M Ω or more
⑨ Insulation Mould	Polycarbonate	Operating Temperature	-20 °C ~ +75 °C
⑩ Terminals	BSP	Terminals	Faston Terminal