






 
Data Sheet - TRU Components

BN: 3089714

Last updated: 28 March 2024

Indicator Light dia.10 mm, Green LED, Black Metal, 12V DC

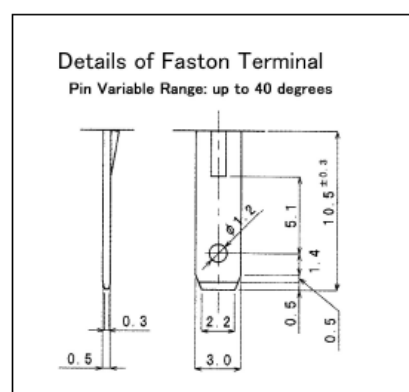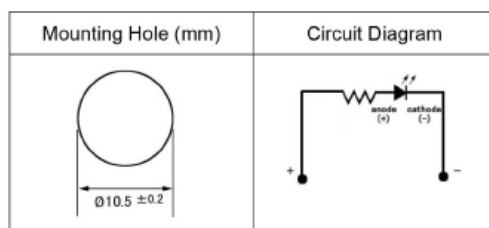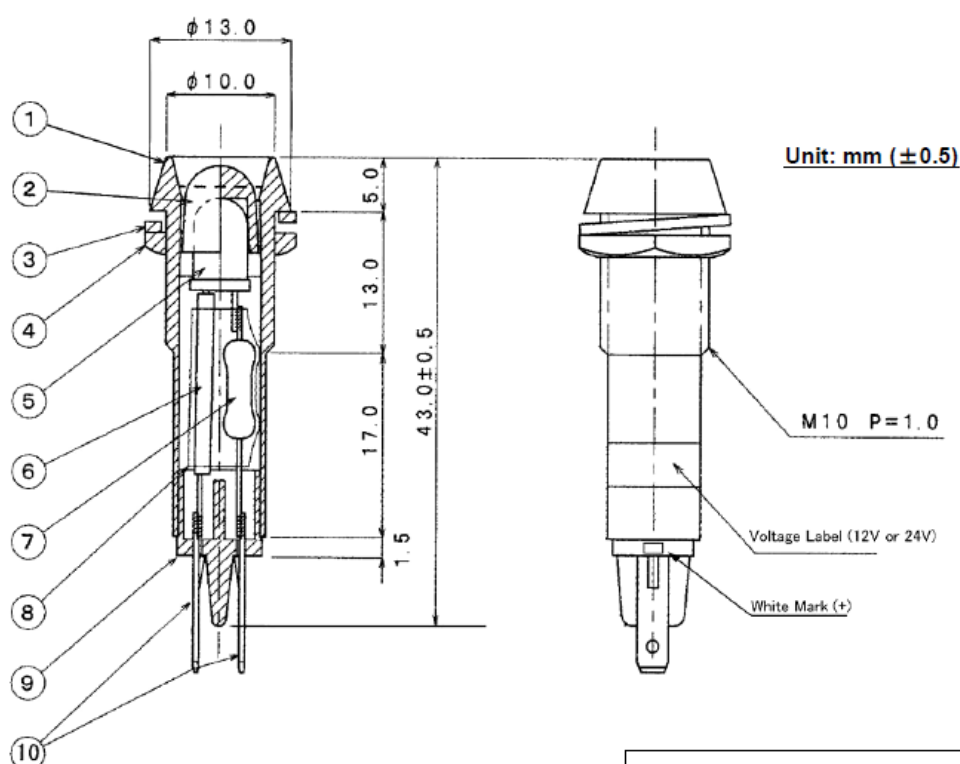

Name of Part		Material		
①	Body (Black)	BSBM2		
②	Lens	Polycarbonate		
③	Spring Washer	SWP		
④	Hex. Nut	BSBM2		
⑤	LED	Green	DATA	
⑥	Insulation Tube	Irrax Tube A	Voltage	DC12V, DC24V
⑦	Insulation Reistor	1W 1.2k Ω	Dielectric strength	AC 1,000 V / minute
⑧	Insulation Tube	Sumi Tube C	Insulation Resistance	DC 500 V 100M Ω or more
⑨	Insulation Mould	Polycarbonate	Operating Temperature	-20 ℃ ~ +75 ℃
⑩	Terminals	BSP	Terminals	Faston Terminal