
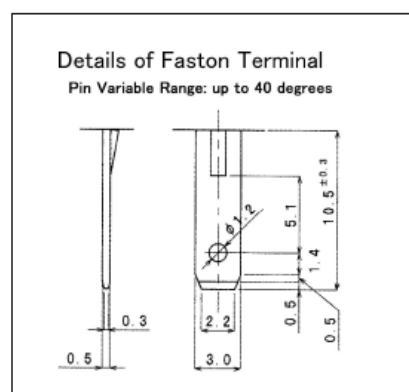
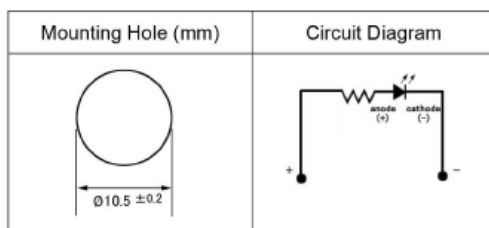


Data Sheet - TRU Components

BN: 3089722

Last updated: 28 March 2024

Indicator Light dia.10 mm, White LED, Black metal, 12V DC

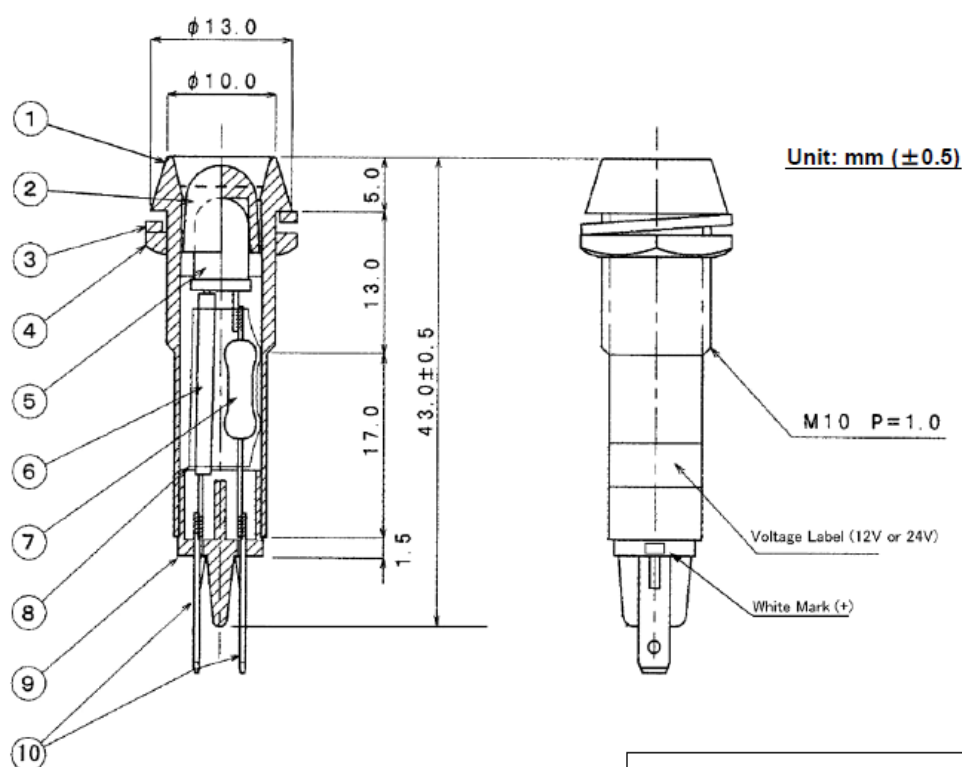

Name of Part	Material	DATA	
① Body (Black)	BSBM2	Voltage	DC12V, DC24V
② Lens	Polycarbonate	Dielectric strength	AC 1,000 V / minute
③ Spring Washer	SWP	Insulation Resistance	DC 500 V 100M Ω or more
④ Hex. Nut	BSBM2	Operating Temperature	-20 $^{\circ}\text{C}$ ~ +75 $^{\circ}\text{C}$
⑤ LED	White	Terminals	Faston Terminal
⑥ Insulation Tube	Irrax Tube A		
⑦ Insulation Resistor	1W 1.2k Ω		
⑧ Insulation Tube	Sumi Tube C		
⑨ Insulation Mould	Polycarbonate		
⑩ Terminals	BSP		