

Seasonic®

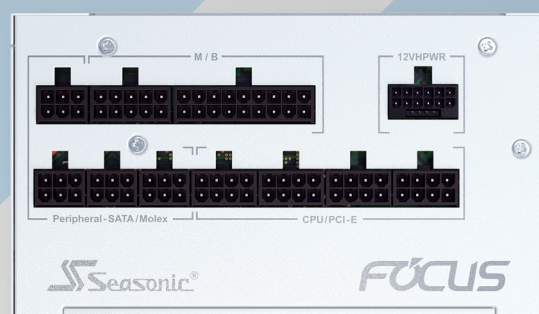
FOCUS GX ATX 3.0

1000 W / 850 W / 750 W



SPECIAL FEATURES

 
 
 
- ❖ ATX 3.0 and PCIe 5.0
- ❖ High Efficiency, 80 PLUS® Gold Certified
- ❖ Fully Modular Cabling Design
- ❖ Native 12VHPWR cable
- ❖ Compact Size (140 mm)
- ❖ 135 mm Fluid Dynamic Bearing (FDB) Fan
- ❖ Seasonic Digital Fan Control
- ❖ Highly Reliable Japanese 105 °C Aluminum Electrolytic Capacitors
- ❖ Tight Voltage Regulation (12 V, 5 V and 3.3 V) [± 3%]
- ❖ Cable-free Connection Design
- ❖ Multi-GPU Technology Support



POWER DISTRIBUTION

Model	+3.3 V	+5 V	+12 V	-12 V	+5 Vsb	Total Power
FOCUS GX-1000	25 A	25 A	83 A	0.3 A	3 A	1000 W
	125 W		996 W	3.6 W	15 W	
FOCUS GX-850	20 A	20 A	70 A	0.3 A	3 A	850 W
	100 W		840 W	3.6 W	15 W	
FOCUS GX-750	20 A	20 A	62 A	0.3 A	3 A	750 W
	100 W		744 W	3.6 W	15 W	

CONNECTOR QUANTITY

Cable							
Model	Main Power (24P / 20P) 610 mm	EPS 12 V / ATX 12 V (8P / 4P) 700 mm	12VHPWR 750 mm	PCI-E (8P / 6P) 750 mm	SATA 950 mm	SATA 3.3 550 mm	Peripheral (4P) 690 mm
FOCUS GX-1000	1	2	1	3	2	1	1
FOCUS GX-850	1	2	1	3	2	1	1
FOCUS GX-750	1	2	1	2	2	1	1

10 YEARS
WARRANTY



Safety & EMI / EMC



Protection Features: OPP / OVP / UVP / SCP / OCP / OTP

Dimensions: 140 mm (L) x 150 mm (W) x 86 mm (H)



Specifications may change without prior notice



Headquarters sales@seasonic.com
USA ssa.sales@seasonic.com
Europe sse.sales@seasonic.com

www.seasonic.com