




Data Sheet - TRU Components

**BN: 3161846/ 3161847/ 3161848/ 3161854/ 3161855/
3161860/ 3161861/ 3161866/ 3161867**

Last updated: 20 March 2025

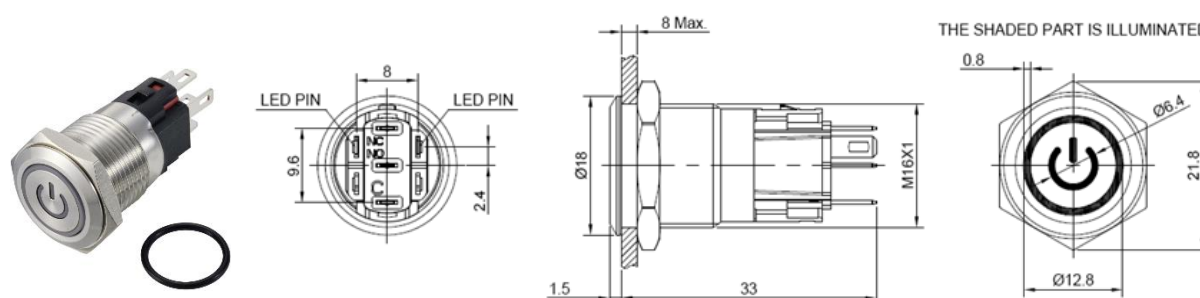

8 Max.: means the panel thickness, the max. thickness for the panel no more than 8 mm

Specification:

BN	Function	LED color	LED Voltage	Material
3161846	Momentary	Red	12-24 V	Stainless steel
3161847		Blue		
3161848		Green		
3161854	Latching	Red		
3161855		Green		
3161860	Momentary	Red		Black anodized aluminum alloy
3161861		Green		
3161866	Latching	Red		
3161867		Green		

Switch rating	3A/250VAC
Mounting diameter	16mm
Head shape.....	Round flat head
Operation type	1NO1NC
Illumination type	Ring and power illumination
Terminal	Pin terminal (2.8X0.5mm)
Operating and storage temperature.....	-25 to +55°C
Mechanical life	1,000,000 (momentary) / 500,000(latching)
Electrical life	50,000 cycles
Dielectric strength	1,500V, RMS 50Hz, 1min.
IP	IP65