




Data Sheet - TRU Components

BN: 3161849/ 3161869

Last updated: 20 March 2025

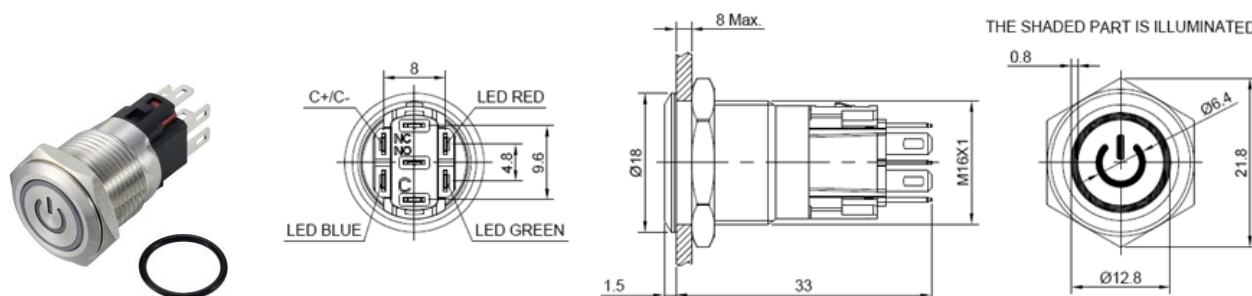

8 Max.: means the panel thickness, the max. thickness for the panel no more than 8 mm

Specification:

BN	Function	LED color	LED Voltage	Material
3161849	Momentary	RGB common anode	12 V	Stainless steel
3161869			24 V	

Switch rating	3A/250VAC
Mounting diameter	16mm
Head shape.....	Round flat head
Operation type	1NO1NC
Illumination type	Ring and power illumination
Terminal	Pin terminal (2.8X0.5mm)
Operating and storage temperature.....	-25 to +55°C
Material	Stainless steel
Mechanical life	1,000,000 (momentary) / 500,000(latching)
Electrical life	50,000 cycles
Dielectric strength	1,500V, RMS 50Hz, 1min.
IP	IP65