


Data Sheet - TRU Components

BN: 3161870/ 3161871/ 3161872/ 3161873/ 3161874/ 3161875

Last updated: 20 March 2025

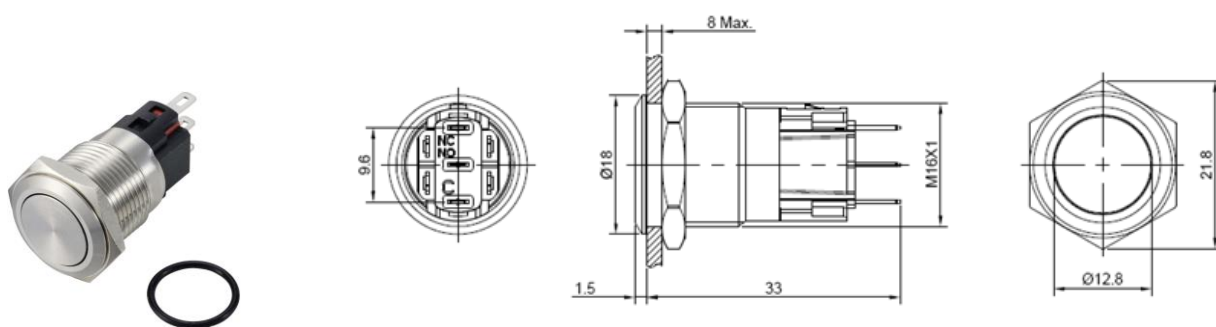

8MAX: means the panel thickness, the max thickness for the panel no more than 8 mm

Specification:

BN	Function	Material
3161870	Momentary	Chrome plated brass
3161871	Latching	Chrome plated brass
3161872	Momentary	Stainless steel
3161873	Latching	Stainless steel
3161874	Momentary	Black anodized aluminum alloy
3161875	Latching	Black anodized aluminum alloy



Switch rating	3A/250VAC
Mounting diameter	16mm
Head shape.....	Round flat head
Operation type	1NO1NC
Illumination type	Non illumination
Terminal	Pin terminal (2.8X0.5mm)
Operating and storage temperature.....	-25 to +55°C
Mechanical life	1,000,000 (momentary) / 500,000(latching)
Electrical life.....	50,000 cycles
Dielectric strength	1,500V, RMS 50Hz, 1min.
IP.....	IP65