

Data Sheet




Neon indicator light, Ø 20 mm, 230 V AC

BN 3164844

BN 3164846



Drawing:

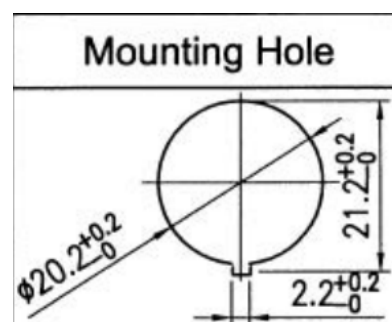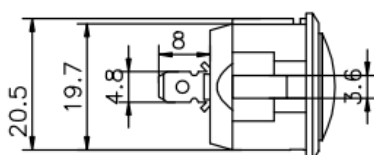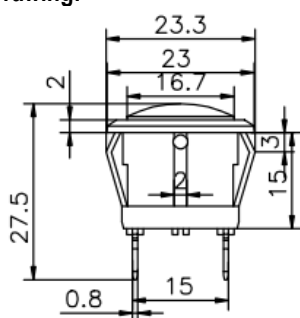

Unit:mm

Technical data

Rating	230 V AC
Insulation Resistance	500 V DC 100 mΩ/min
Dielectric Strength	1500 V AC 1 minute
Operation Temp.	-20 °C to +80 °C
Materials:	
Frame	Nylon PA66
Lens	PC
Color	Red (BN 3164844) Green (BN 3164846)