


Data Sheet

2 pc type, 316 Stainless Steel ball valve

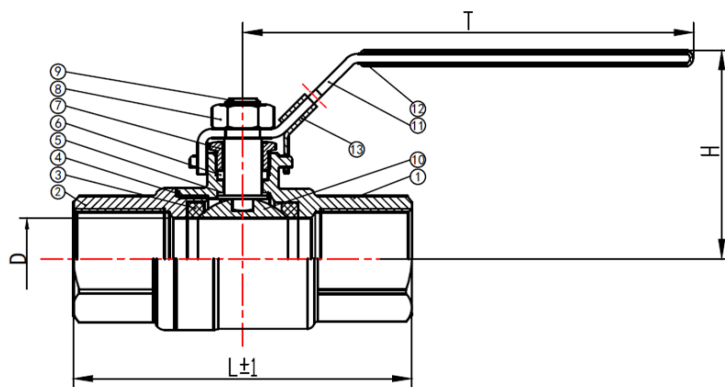

MAIN PARTS MATERIALS:

NO.	PART NAME	MATERIAL	QTY
1	BODY	SS316	1
2	CAP	SS316	1
3	SEAT	PTFE	2
4	JOINT GASKET	PTFE	1
5	THRUST WASHER	PTFE	1
6	PACKING	PTFE	1
7	GLAND	SS	1
8	NUT	SS	1
9	STEM	SS316	1
10	BALL	SS316	1
11	HANDLE	SS201	1
12	HANDLE COVER	PVC	1
13	LOCK	SS201	1

Item No.	3192587	3192588	3192589	3192590	3192591	3192592
Size	G1/2"	G3/4"	G1"	G1 1/4"	G1 1/2"	G2"
DN	15	20	25	32	40	50
DN	15	20	25	32	40	50
L	75	80	90	110	120	140
H	60	64	68	76	84	92
T	104	119	123	144	158	168
weight (Kg)	0.281	0.401	0.577	0.834	1.308	1.793

- Valve Standard: DIN3202-M3
- Thread: BSP
- Rated pressure: 64 bar
- Temperature: -40 – 210 °C
- Material: Stainless Steel