

Item no.: 3193111, 3193112, 3193113, 3193114, 3193115,
3193484. 3193485

Data Sheet

Solenoid Valve




Item No.	3193111	3193112	3193113	3193114	3193115
Valve Type	5/2 way	5/2 way	5/2 way	3/2 way	3/2 way
Effective Cross Section Area	12 mm ²	14 mm ²	16 mm ²	14 mm ²	14 mm ²
Port Size	G 1/8"	G 1/8"	G 1/4"	G 1/8"	G 1/4"
Working Medium	40 Micron Filtered Air				
Operation	Internal piloted				
Working pressure	1.5 - 8 bar				
Max. Test pressure	12 bar				
Ambient Temperature	-5 - 50 °C				
Connector Protection	F Class, IP 65				
Wiring/ Connector	Cable / Lead Wire				
Switching Frequency	5 Cycles/sec.				
Response Time	0.05 Sec.				

Item no.: 3193111, 3193112, 3193113, 3193114, 3193115,
3193484, 3193485


Data Sheet

- Drawings


Item No. 3193111

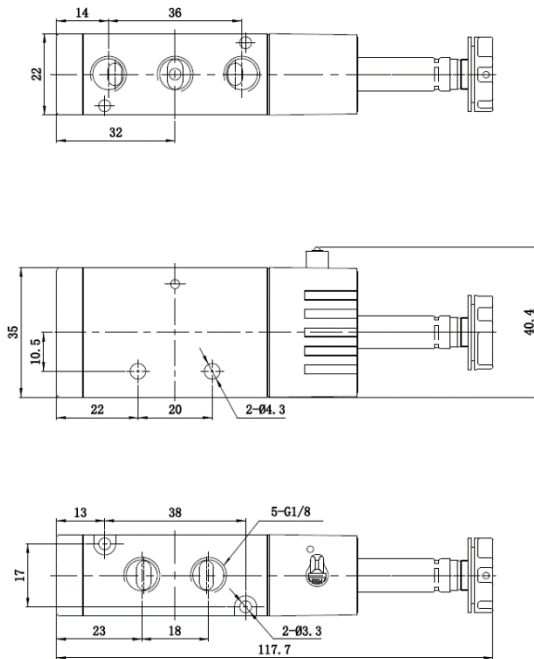


Item No. 3193112

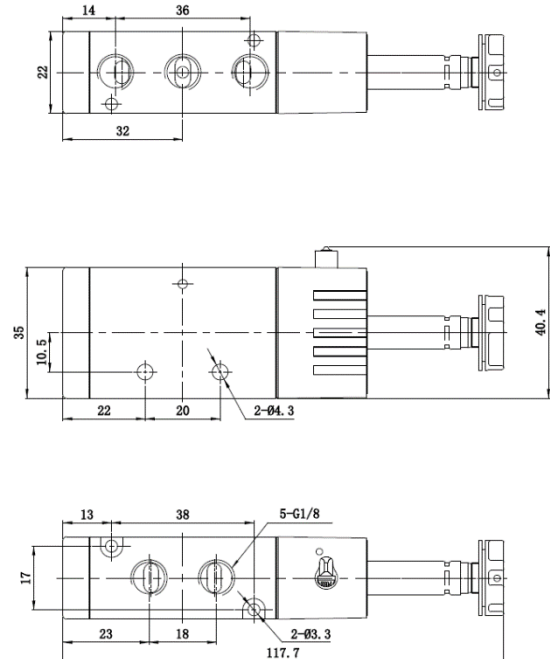

Item No. 3193113

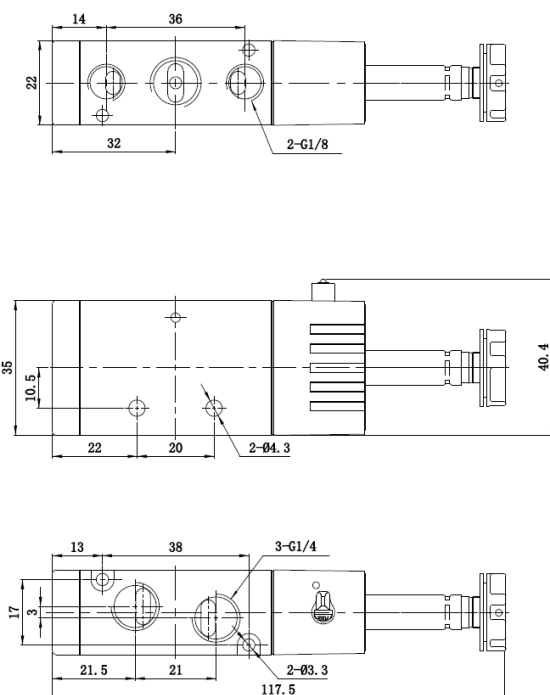


Item No. 3093114

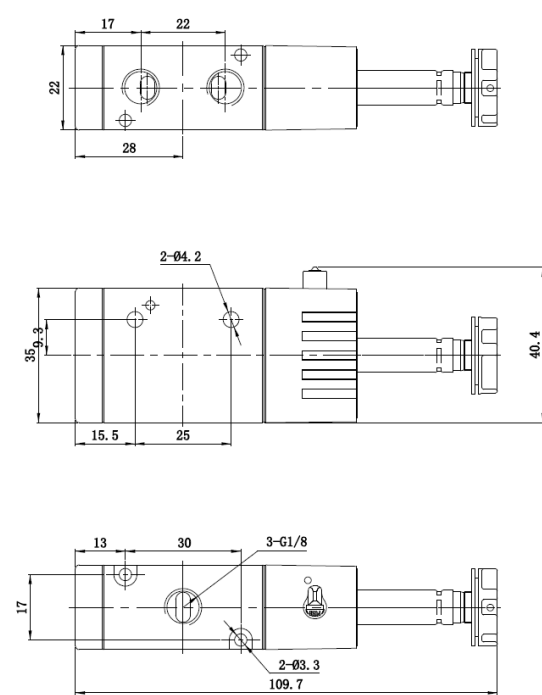

Item no.: 3193111, 3193112, 3193113, 3193114, 3193115,
3193484. 3193485

Data Sheet

Item No. 3093115

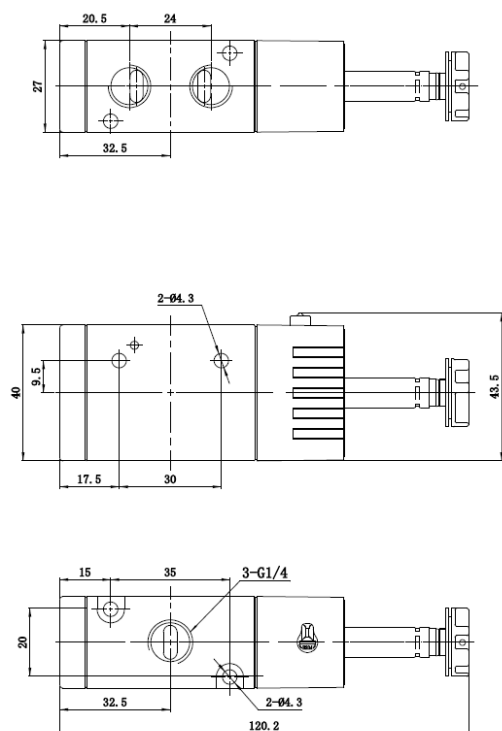

Coil with wire connector

Item No.	3193484	3193485
Suitable for Item No.	3193111, 3193112	3193112, 3193113, 3193114, 3193115
Power	2.5 W	3 W
Working voltage	24 V/DC	
Ambient Temperature	-30 - 70 °C	
Protection class	IP65	
Insulation class	F Class	
Wiring Form	Lead Wire Type	

Item no.: 3193111, 3193112, 3193113, 3193114, 3193115,
3193484. 3193485

Data Sheet

- Drawings

