


# COMBO MIMO MOBILE ROOF SMA ANTENNA

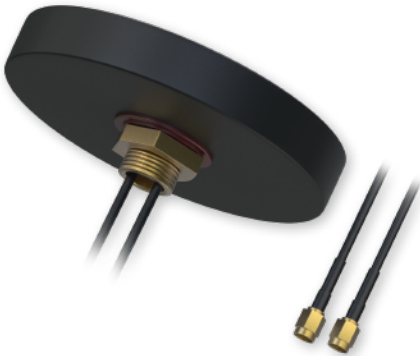

## TECHNICAL DATA

### MECHANICAL/ENVIRONMENTAL

|                                  |                                |
|----------------------------------|--------------------------------|
| Mounting method                  | Screw                          |
| Radome ingress protection rating | IP65 (exclude cable outlet)    |
| Radome material                  | UV resistant plastic and cable |
| Housing dimensions               | Ø 81.3 x 15.2 mm               |
| Cable                            | 2x RG174, 3000 mm              |
| Operating temperature            | -40 ~ +85 °C                   |
| Weight                           | 157 ± 10 g                     |
| UV resistance                    | ✓                              |
| RoHS Compliant                   | ✓                              |

### LTE ANTENNA

|                          |                            |
|--------------------------|----------------------------|
| Frequency range          | 698 - 960, 1710 - 2690 MHz |
| Polarization             | Linear                     |
| Main antenna gain        | 2.5 dBi                    |
| Aux antenna gain         | 2.0 dBi                    |
| V.S.W.R                  | <3.0                       |
| Impedance                | 50 Ω                       |
| Connector type and count | 2x SMA Male                |

