

imou



IMOU
SENSE

Full Color

Cruiser Dual

6MP Dual Lens Outdoor P&T Camera

Cruiser Dual 6MP have two lens(3MP Fixed lens and 3MP PT lens), two lenses can independently monitor scenes from different angles, Makes one Cruiser Dual worth 2 traditional monocular cameras. Fixed Lens supports manual angle adjustment within the range of 0~260° pan & 0~30° tilt; PT Lens supports motorized angle adjustment from 0~355° pan & 0~90° tilt; Cruiser Dual ensures every corner of your home completely covered. It supports four night vision modes for clear-as day clarity even in pitch dark. With IP66 certified, the camera can be used outdoors under different weather conditions. With built-in spotlight and security siren, Cruiser Dual enables high-quality two-way talk; It also supports IMOU's self-developed algorithm (IMOU SENSE), which supports human detection and vehicle detection, greatly reducing the rate of false alarms while bringing better protection to home security



Two lens resolution total 6MP
3MP Fixed Lens + 3MP Pan & Tilt Lens



AI Human & Vehicle Detection
Quickly find human/vehicle targets



Smart Color Night Vision
Support four-mode night vision for clear-as day clarity even in pitch dark



Active Deterrence
Scare away unwelcome visitors with built-in spotlight and 110dB security siren



IP66
Weatherproof from dust and water



Two-way Talk
Real-time communicate with people at the camera




Smart Tracking
Automatically tracks moving objects



Alarm Notification
Sends instant motion-activated alerts to your mobile phone



Wi-Fi Connection
IEEE802.11 ax/b/g/n(2.4GHz)

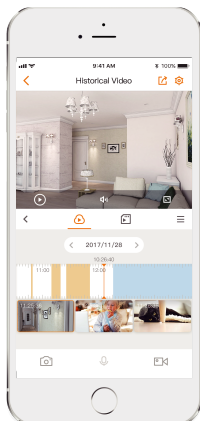

Stay close with what you care

With Cloud service, you will have access to what you care as long as Internet is available. You can record daily or motion videos on Cloud and play back anytime anywhere.

Specifications



Camera

Fixed Lens:

1/2.8" 3 Megapixel Progressive CMOS
3MP (2304x 1296)

Night Vision: 30m(98ft) Distance

3.6mm Fixed Lens

Field of View: 88° (H), 45° (V), 107° (D)

0~260° Pan & 0~30° Tilt

Pan & Tilt Lens:

1/2.8" 3 Megapixel Progressive CMOS
3MP (2304x 1296)

Night Vision: 30m(98ft) Distance

3.6mm Fixed Lens

Field of View: 88° (H), 45° (V), 107° (D)

0~355° Pan & 0~90° Tilt

Video & Audio

Video Compression : H.265/H.264

Up to 15 fps Frame Rate

8x Digital Zoom

Built-in Mic & Speaker, 110dB Siren

Two-way Audio

Notice Management

Motion Detection

Configurable Region

Human Detection

Vehicle Detection

Network

1 x 100Mbps Ethernet Port

Wi-Fi 6: IEEE802.11 b/g/n/ax

Imou App: iOS, Android

Auxiliary Interface

Micro SD Card Slot (up to 256GB)

Built-in Mic & Speaker

Reset Button

General

DC 12V1A Power Supply

Power Consumption: <12 W

Material: Plastic

Working Environment: -30° C ~ +50° C, Less Than 95%RH

Dimensions: 158.72 × 124.98 × 201.9mm (6.25 × 4.92 × 7.95 inch)

Weight: 642g (1.42lb)

CE

IP66

What's in the box

- 1x Camera
- 1x Quick Start Guide
- 1x Power Adapter
- 1x Mounting Template
- 1x Waterproof Connector
- 1x Screw and Anchor pack

