

imou



Full  Color

Bulb Cam

3MP Wireless PTZ Bulb Camera

Bulb Cam delivers 3MP live monitoring with a choice of 2.8mm lens option, With 0~340° pan & 0~90° tilt features, Bulb Cam 3MP ensures every corner of your home completely covered. It supports full-color night vision for clear-as day clarity even in pitch dark. The installation method of thread mount brings you great convenience. With security siren, Bulb Cam 3MP actively keeps unwelcome visitors away from what you care about.



3MP 2K Video
See more than 1080P



AI Human & Vehicle Detection
Quickly find human/vehicle targets



Full Color Night Vision
Support full-color night vision for clear-as day clarity even in pitch dark



Active Deterrence
Scare away unwelcome visitors with security siren



Two-way Talk
Real-time communicate with people at the camera



Smart Tracking
Automatically tracks moving objects



Diversified Storage
Supports Cloud Storage or Micro SD card (up to 256GB)




Alarm Notification
Sends instant motion-activated alerts to your mobile phone



Wi-Fi Connection
IEEE802.11 b/g/n(2.4GHz)






Privacy Mode
Hide the lens to protect your personal privacy

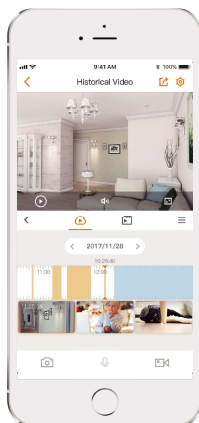

Stay close with what you care

With Cloud service, you will have access to what you care as long as Internet is available. You can record daily or motion videos on Cloud and play back anytime anywhere.

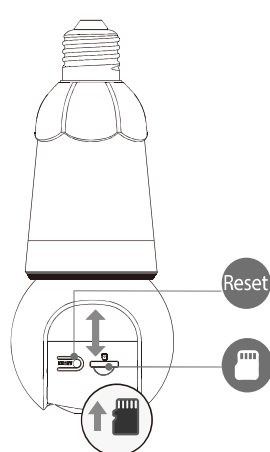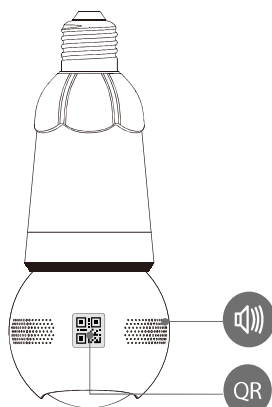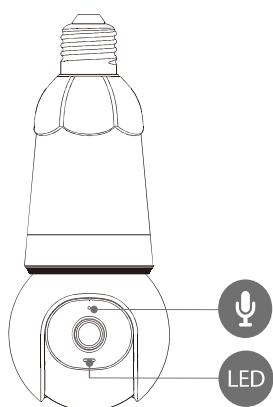

Specifications

Camera

3 Megapixel Progressive CMOS
3MP (2304 x 1296)
Night Vision: 25 m (82 ft)
2.8mm Fixed Lens
Field of View: H: 98° D: 121° V: 54°
0~340° Pan & 0~90° Tilt

Video & Audio

Video Compression : H.265/H.264
Up to 15 fps Frame Rate
8x Digital Zoom
Built-in Mic & Speaker, Siren
Two-way Audio

Notice Management

Motion Detection
Configurable Region
Human Detection
Vehicle Detection

Network

Wi-Fi: IEEE802.11 b/g/n/ax, 2.4GHz
Imou App: iOS, Android
ONVIF

Auxiliary Interface

Micro SD Card Slot (up to 256GB)
Built-in Mic & Speaker
Reset Button

General

Power Supply Voltage: 100~240 V
Power Consumption: < 15W
Bulb Consumption: 5.2W
350 Lumen Brightness
Material: Plastic+Metal
Working Environment: -10°C ~ +45°C (+14°F~+113°F)
Dimensions: 37.5 mm*37.5 mm*175 mm
Weight: 265 g (0.58 lb)
CE, UKCA, WWA

What's in the box

- 1x Camera
- 1x Quick Start Guide

