

DATASHEET

Metal Barb Cable Ties, 100pcs / bag

Item No. 3203536

Item No. 3203537

Item No. 3203538

Item No. 3203539

Item No. 3203540

Item No. 3203545

Item No. 3203546

Item No. 3203535


Item No. 3203547

Item No. 3203548

Item No. 3203549

Item No. 3203550

Product drawing

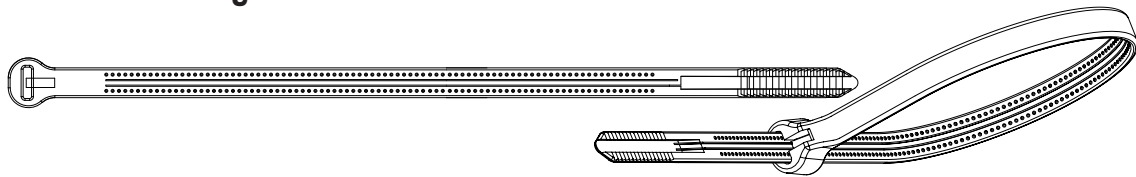

Technical Data

Item No.:	Length (mm)	Width (mm)	Lock measurements (W/L/H)	Thickness of cable tie	Min./Max. Bundle diameter (mm)	Tensile strength (kg)	Newton (N)	Color
3203536	100	3	5.9/4.5/4	1.1	3/20.5	8.1	80	Natural
3203537	140	3.6	6/5/4	1.25	3.5/33.0	18.3	180	Natural
3203538	200	4.8	8.25/6/5.5	1.25	3.5/49.5	22.7	222	Natural
3203539	300	4.8	8.25/6/5.5	1.25	3.5/81.0	22.7	222	Natural
3203540	370	4.8	8.25/6/5.5	1.25	3.5/103.5	22.7	222	Natural
3203545	370	7	12.9/9/8.2	1.7	8.5/103.5	55.1	540	Natural
3203546	100	3	5.9/4.5/4	1.1	3/20.5	8.1	80	Black
3203535	140	3.6	6/5/4	1.25	3.5/33.0	18.3	180	Black
3203547	200	4.8	8.25/6/5.5	1.25	3.5/49.5	22.7	222	Black
3203548	300	4.8	8.25/6/5.5	1.25	3.5/81.0	22.7	222	Black
3203549	370	4.8	8.25/6/5.5	1.25	3.5/103.5	22.7	222	Black
3203550	370	7	12.9/9/8.2	1.7	8.5/103.5	55.1	540	Black

Flammability ratingUL94 V2
 Plenum ratedAH-2
 Metal tongue (barb)316 stainless steel
 Minimum holding force8.1 kg
 Operating temperature-60 to 85 °C
 Storage relative humidity50 % RH
 Min. installation temperature-20 °C
 Max. sustainable temperature (short time)+110°C
 Material.....Polyamide (Nylon) 6.6
 Colournatural
 Comply withUL62275 / CAS C22.2