

DATASHEET

Cable Ties With Screw Fastening, 100pcs / bag

Item No. 3203551

Item No. 3203542


Item No. 3203543

Item No. 3203541

Item No. 3203552

Item No. 3203544

Product drawing

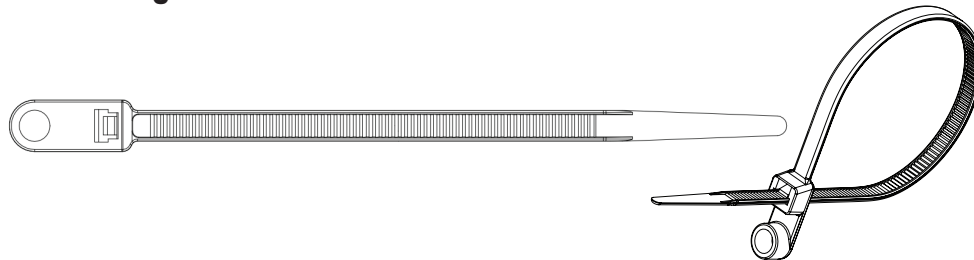

Technical Data

Item No.:	Length (mm)	Width (mm)	Lock measurements (W/L/H)	Thickness of cable tie	Min./Max. Bundle diameter (mm)	Tensile strength (kg)	Newton (N)	Color
3203551	200	4.8	7.8/20/5.2	1.2	3/49.8	8.1	222	Natural
3203541	370	4.8	7.8/20/5.2	1.2	3/103.8	8.1	222	Natural
3203542	400	7.6	13.5/28.4/7.6	1.75	3/109.2	55.1	540	Natural
3203552	200	4.8	7.8/20/5.2	1.2	3/49.8	8.1	222	Black
3203543	370	4.8	7.8/20/5.2	1.2	3/103.8	8.1	222	Black
3203544	400	7.6	13.5/28.4/7.6	1.75	8/109.2	55.1	540	Black

Flammability ratingUL94 V2
 Plenum ratedAH-2
 Minimum holding force222 N
 Operating temperature-40 to 85 °C
 Storage relative humidity50 % RH
 Min. installation temperature-10 °C
 Max. sustainable temperature (short time)+110°C
 Material.....Polyamide (Nylon) 6.6
 Colournatural / Black
 Comply withUL62275 / CAS C22.2