


Data Sheet

Latest version 27 Sept 2024

Dia. 19 mm Push Button

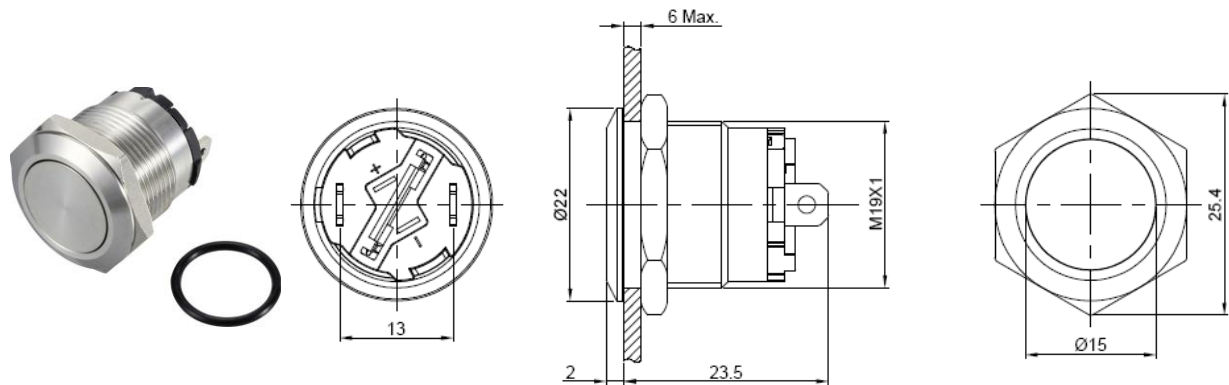

6 MAX.: means the panel thickness, the max thickness for the panel no more than 6mm.

BN 3204908: Momentary

BN 3204909: Latching

Switch rating.....	20A/250VAC
Mounting diameter.....	19mm
Head shape.....	Round head
Operation type.....	1NO momentary / latching
Illumination type	Non illumination
Terminal	Pin terminal (4.8 X 0.8mm)
Operating and storage temperature	-25 to +55°C
Operating and storage humidity	20 to 80 % RH
Material.....	Stainless steel
Mechanical life	1,000,000 (momentary) / 500,000 (latching)
Electrical life	50,000 cycles
Dielectric strength.....	1500V, RMS 50HZ, 1 minute
Insulation resistance.....	≥ 100MΩ
IP degree.....	IP67