

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For more than 40 years, our product range has been dynamically adapting to the constant changes in the industry. We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

HR6 NI-MH 1800 MAH (AA) RECHARGEABLE BATTERY



Item No.:	Qty.
3205202	4


TECHNICAL DATA

Type:	AA HR6
Classification:	Rechargeable
Chemical system:	Ni-MH
Nominal voltage:	1.2 V
Capacity	1800 mAh
Weight (approx.):	130 g
Operating conditions:	Charge: -10 to +40 °C Discharge: -30 to +70 °C Humidity: <65 % RH
Storage conditions:	-20 to +35 °C, <65 % RH


*For performance and safety, observe the operating / storage conditions.

DIMENSIONS

D	13.8~14.5mm
H	49.0~50.5mm
D1	5.4 ± 0.2mm
H1	1.5 ± 0.3mm

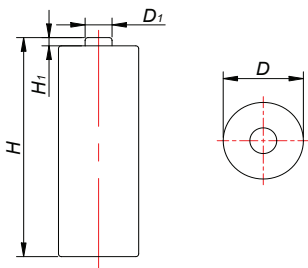

CHARGING CHARACTERISTICS

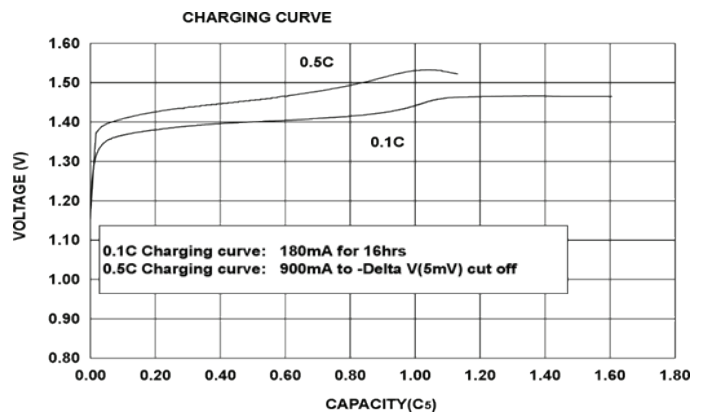

DISCHARGE CHARACTERISTICS

