


Data Sheet

Push button switch

Version 10/24

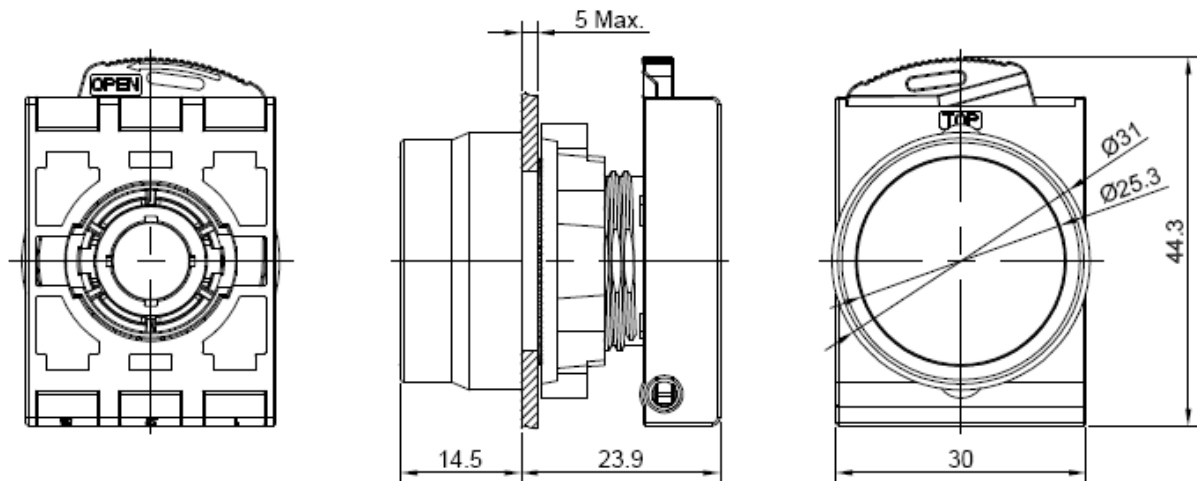

Specification

Mounting diameter.....	22 mm
Head shape	Round head
Operation type.....	Momentary/latching
Operating and storage temperature	-25 to +55°C
Operating and storage humidity	45 to 85 % RH
IP rating	IP40
Mechanical lifetime.....	1,000,000 (momentary) / 500,000(latching)
Electrical lifetime	50,000 cycles
Dielectric strength.....	3000V, AC 50HZ, 1 minute
Insulation resistance.....	≥ 100MΩ

Item no.	Operation type	Head color
3208806	Momentary	Red
3208807	Momentary	Green
3208808	Momentary	White
3208809	Latching	Red
3208810	Latching	Green
3208811	Latching	White