


Data Sheet

Selector switch

Version 10/24

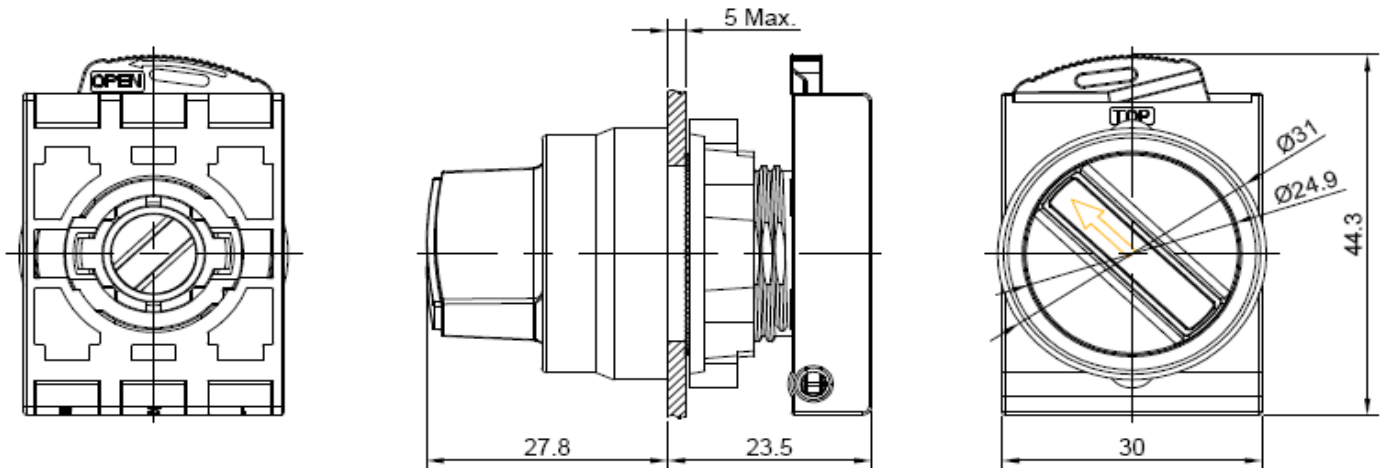

Specification

Mounting diameter.....	22 mm
Head shape	Round head
Operation type.....	Two position maintain
Operating and storage temperature	-25 to +55°C
Operating and storage humidity	45 to 85 % RH
IP rating	IP40
Mechanical lifetime.....	500,000 cycles
Electrical lifetime	50,000 cycles
Dielectric strength.....	3000V, AC 50HZ, 1 minute
Insulation resistance.....	$\geq 100\text{M}\Omega$