


Data Sheet

Contact socket

Version 06/24

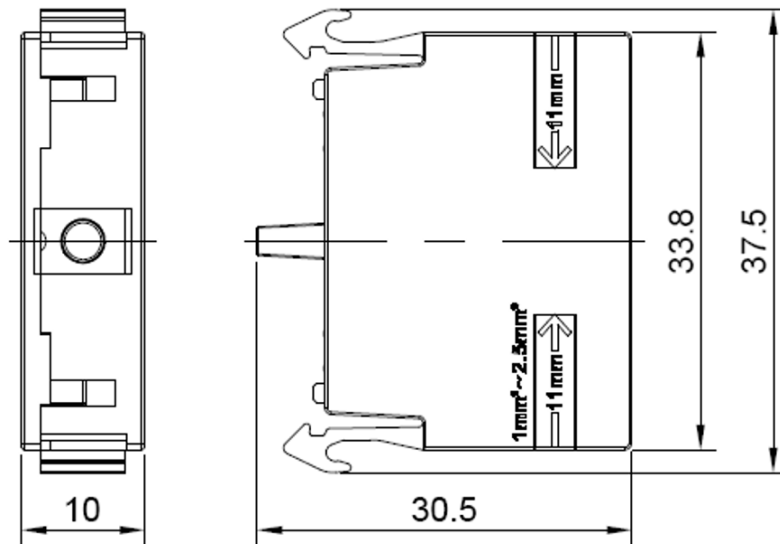

Specification

Switch rating.....	I _e /U _e : 5 A / 250 VAC
Operating and storage temperature	-25 to +55 °C
Operating and storage humidity	45 to 85 % RH
Mechanical lifetime.....	1,000,000 (momentary) / 500,000(latching)
Electrical lifetime	50,000 cycles
Dielectric strength.....	3000V, AC 50HZ, 1 minute
Insulation resistance.....	≥ 100MΩ

Item no.	Function
3208822	1NO
3208823	1NC