





Data Sheet

Touch switch

Version 1/25

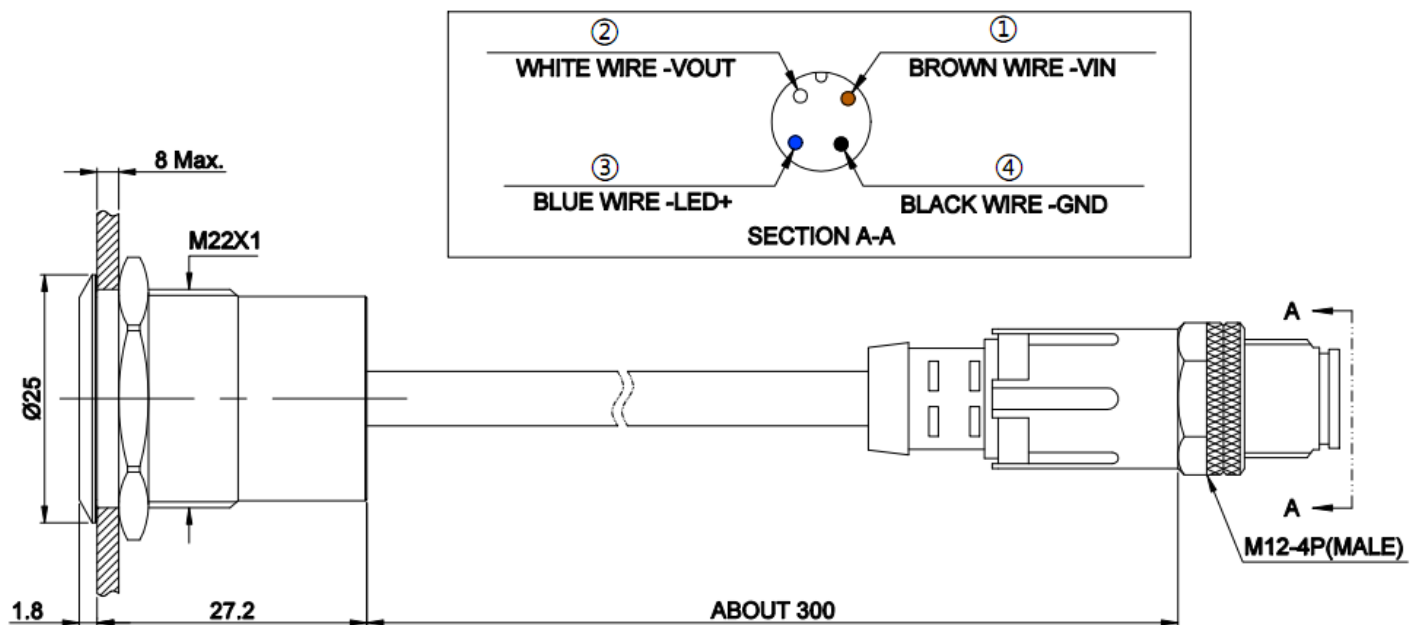

THE SHADED PART IS ILLUMINATED

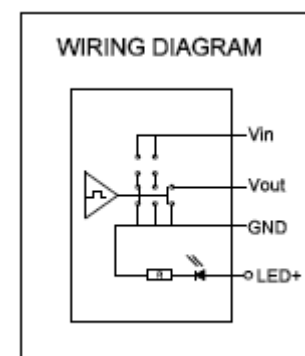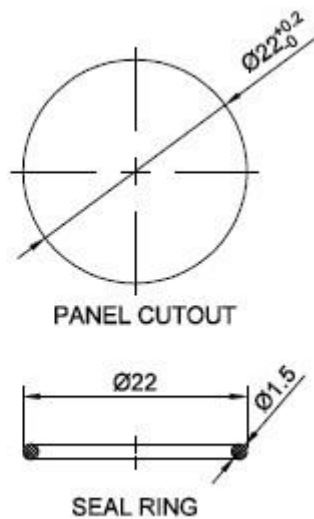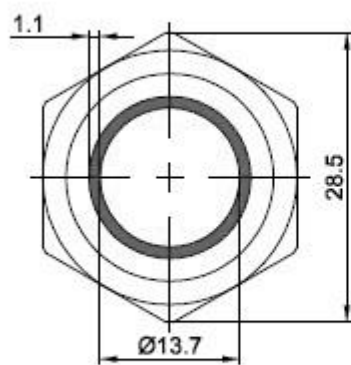

Data Sheet

Specification

Mounting diameter.....	22 mm
Head shape.....	Round head
Operation type.....	Momentary
Switch rating .	500 mA / 24 VDC
Insulation resistance	600 VDC 10 MΩ
Contact resistance	20 mΩ
Contact structure	1NO
Output Type	PNP
Terminal	Wire with M12 male connector
Body material	Stainless steel
Lighting type	LED 12 V
Operating force	0 N
Operating and storage temperature	-25 to +55°C
Operating and storage humidity	20-80%RH(no condensation)
Electric life	50 million cycles

Item no.	Head color
3208824	None (Standby), Red (Active)
3208825	None (Standby), Green (Active)