


Data Sheet

LIMIT SWITCH

Version 06/24

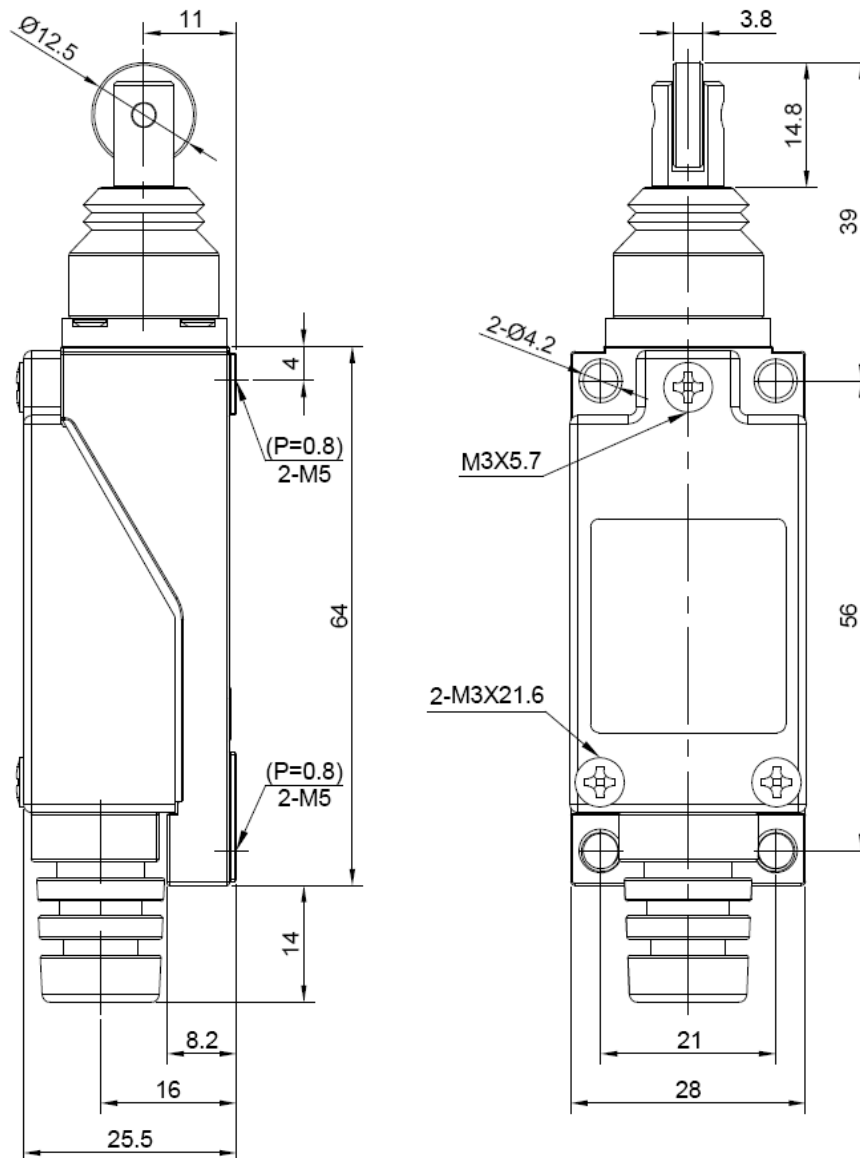

Specification

Rating	5 A / 250 VAC
Operating and storage temperature	-5 to +65°C
Operating and storage humidity	<95 % RH
IP rating	IP65
Mechanical lifetime	10,000,000 cycles
Electrical lifetime	500,000 cycles
Insulation resistance	$\geq 100\text{M}\Omega$