


Item number: 3208868

Product name : In Line Fuse Holder - For Mini Fuse, Rubber TPV



SPECIFICATION :

- *The In-Line Fuse Holder is designed for the Mini type
- *Electrical: 30A MAX.
- *Insulation Body: TPV
- *Terminal: Brass
- *Available wire gauge: UL 1015 12# AWG , G/6" inch Each End
- *Product meet ROHS. Product not UL Listed.

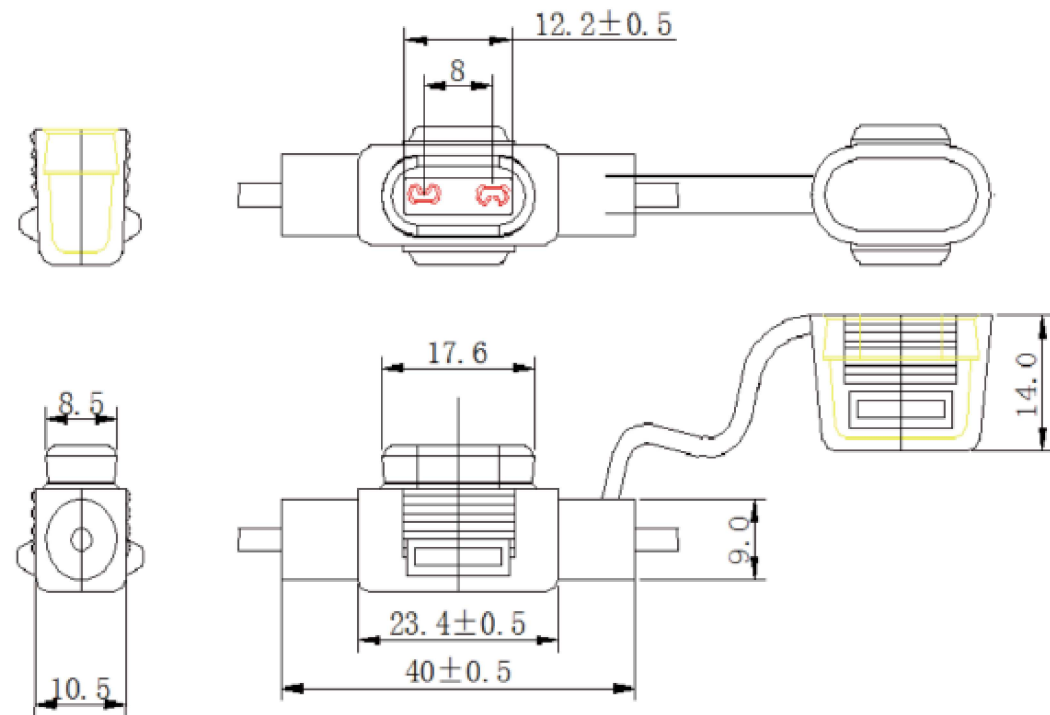

***If changed without any notice advance.**

Customer	Internal		PO#	N/A
Model No.	C001-028-0008RU		Description	IN-LINE-FUSE HOLDER
Quantity	5pcs	Specifications	#UL1015 12AWG 150mmx2	

Inspection Item		Standard	No.					OK/NG
			1	2	3	4	5	
1	電性測試 200% Electrical	Within 0.15~5s	2.84	3.66	2.97	3.83	4.60	OK

Inspection Item		Standard	No.					NG/OK
			1	2	3	4	5	
Dimension	Appearance	Appearance should be good, no cracks or deformations	PASS	PASS	PASS	PASS	PASS	OK
	1	150±5mm	151.0	152.0	151.0	152.0	151.0	OK
	2	40±0.5	39.89	39.97	39.90	39.92	39.93	OK
	3	150±5mm	151.0	152.0	151.0	151.0	151.0	OK