

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For decades, our product range has been dynamically adapting to the constant changes in the industry.

We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

HR6 NI-ZN 1500 MAH (AA) RECHARGEABLE BATTERY



Item No.:	Qty.
3208871	8
2542803	4


TECHNICAL DATA

Type:	AA HR6
Classification:	Rechargeable
Chemical system:	Ni-Zn
Nominal voltage:	1.6 V
Capacity	1500 mAh
Weight (approx.):	260 g
Operating conditions:	Charge: 0 to +40 °C Discharge: -10 to +50 °C Humidity: <65 % RH
Storage conditions:	-20 to +35 °C, <65 % RH


*For performance and safety, observe the operating / storage conditions.

DIMENSIONS


D	13.8 - 14.5mm
H	49.5 - 50.5mm
D1	5.4 ± 0.2mm
H1	1.5 ± 0.3mm

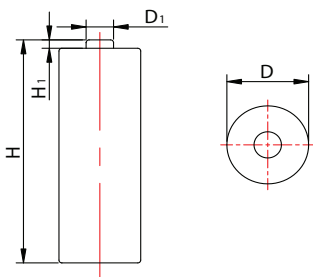

CHARGING CHARACTERISTICS

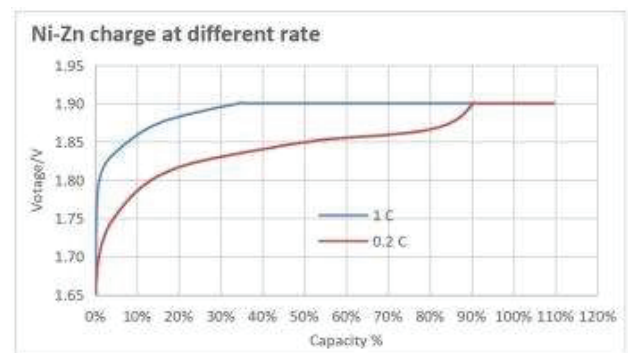

DISCHARGE CHARACTERISTICS

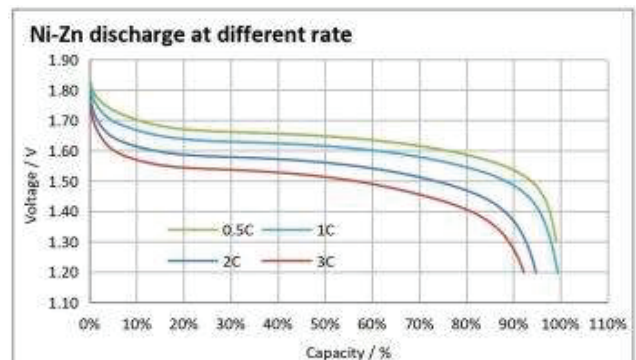

PRODUCT LIFE CYCLE

